


8702SFO3V02S

NEMA Contactor, Type S, reversing, Size 4,
135A, 3 pole, 3 phase, horizontal, 110/120
VAC 50/60 Hz coil, open style

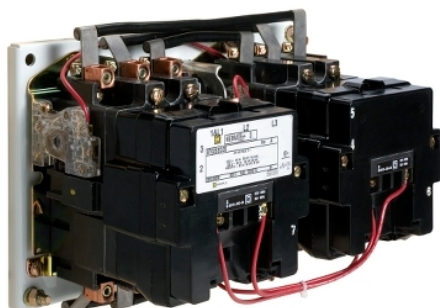

Main

Product Type	Contactors
Product Range	Type S
Contactors Type	Reversing

Complementary

NEMA Size	4
Rated Current	135 A
Number of Poles	3P
Mounting Orientation	Horizontal
Maximum Voltage Rating	600 V AC
Phase	3 phase
Horsepower Rating	40 HP 200 V AC 50 HP 230 V AC 100 HP 460 V AC 100 HP 575 V AC
Coil Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Control Circuit Type	Separate control circuit
Control Units	No control units
Other Equipment	Fuse not supplied
Terminal Type	Screw clamp terminals
Height	11.69 in (297 mm)
Width	14.25 in (362 mm)
Depth	7.01 in (178 mm)

Environment

Enclosure Type	Not rated (open device)
Certifications	CSA UL Listed

Ordering and shipping details

Category	21273 - 8702,36 SE,SF(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901841319
Nbr. of units in pkg.	1
Package weight(Lbs)	44 lb(US) (19.96 kg)
Returnability	No
Country of origin	MX

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
EU RoHS Directive	Not compliant
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------