



Main

Range of product	Altivar
Range compatibility	Altivar 12 Altivar 312 Altivar 312 Solar
Product compatibility	ATV12HU22M2 ATV12HU22M3 ATV12PU22M3 ATV312HU22M2 ATV312HU22M3 ATV312HU30M3
Average power available	28 W 122 °F (50 °C) 32 W 104 °F (40 °C)
Ohmic value	68 Ohm

Complementary

Net Weight	1.37 lb(US) (0.62 kg)
------------	-----------------------

Environment

IP degree of protection	IP00
-------------------------	------

Ordering and shipping details

Category	22042 - ATV12 DRIVE AND ACCESSORIES
Discount Schedule	CP4B
GTIN	00785901134442
Nbr. of units in pkg.	1
Package weight(Lbs)	1.34 lb(US) (0.61 kg)
Returnability	No
Country of origin	FR

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	2.83 in (7.2 cm)
Package 1 width	6.69 in (17 cm)
Package 1 Length	9.25 in (23.5 cm)
Unit Type of Package 2	P06
Number of Units in Package 2	56
Package 2 Weight	104.10 lb(US) (47.22 kg)
Package 2 Height	31.50 in (80 cm)
Package 2 width	31.50 in (80 cm)
Package 2 Length	23.62 in (60 cm)

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.


Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------

Dimensions

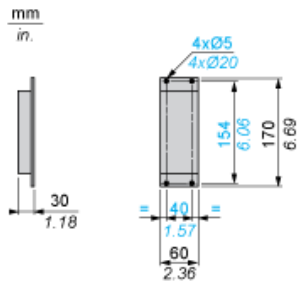

Clearance

