


9422ATF11

Operating mechanism, flange mounted, variable depth, 200A, 600V, no fuse, switch mechanism, 6 inch handle, NEMA 4

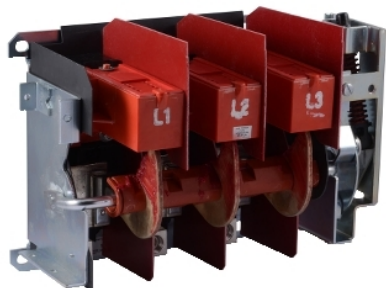

Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Non-fusible disconnect switch

Complementary

Mounting Type	Flange rod variable depth
Current Rating	200 A
Horsepower Rating	40 Hp 200 V AC 60 Hp 230 V AC 125 Hp 460 V AC 150 Hp 575 V AC 40 Hp 250 V DC 50 hp 600 V DC
Handle Type	6 in handle included NEMA 1/3/3R/4 enclosures sheet steel

Environment

Certifications	UL Recognized CSA
----------------	----------------------

Ordering and shipping details

Category	21732 - 9422
Discount Schedule	CP1
GTIN	00785901120308
Nbr. of units in pkg.	1
Package weight(Lbs)	23.97 lb(US) (10.87 kg)
Returnability	Yes
Country of origin	MX

Packing Units

Unit Type of Package 1	PCE
Package 1 Height	9.20 in (23.368 cm)
Package 1 width	12.10 in (30.734 cm)
Package 1 Length	20.90 in (53.086 cm)

Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov
EU RoHS Directive	Compliant EU RoHS Declaration
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS Declaration

Contractual warranty

Warranty	18 months
----------	-----------