


# 9422ATCF301

Operating mechanism, flange mounted, variable depth, 30A, 250 V, fuseholder, switch mechanism, 6 inch handle, NEMA 4

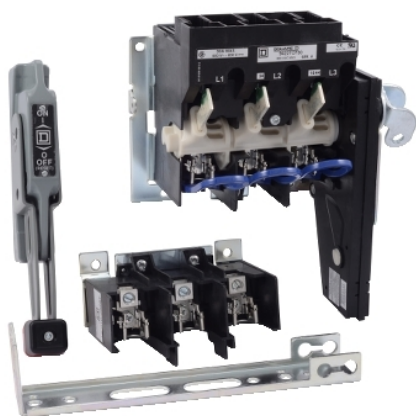

## Main

Range	9422T
Product	Disconnect Switch
Disconnect Type	Fusible disconnect switch

## Complementary

Mounting Type	Flange rod variable depth
Current Rating	30 A
Horsepower Rating	7.5 Hp 200 V AC 7.5 Hp 230 V AC 15 Hp 460 V AC 20 Hp 575 V AC 5 hp 250 V DC
Fuse Rating	30 A 250 V
Handle Type	6 in handle included NEMA 1/3/3R/4 enclosures sheet steel
Fuse Type	H K J R

## Environment

Certifications	UL Recognized CSA
----------------	----------------------

## Ordering and shipping details

Category	21732 - 9422
Discount Schedule	CP1
GTIN	00785901872153
Nbr. of units in pkg.	1
Package weight(Lbs)	8.8 lb(US) (3.99 kg)
Returnability	No
Country of origin	MX

## Packing Units

Package 1 Height	7.30 in (18.542 cm)
Package 1 width	11.30 in (28.702 cm)
Package 1 Length	16.00 in (40.640 cm)

## Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
EU RoHS Directive	Compliant <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
PVC free	Yes

## Contractual warranty

Warranty	18 months
----------	-----------