


# 8501XUDO40V63

NEMA Control Relay, Type X, utility, 10A resistive at 600 VAC, 4 normally open contacts, 125 VDC coil

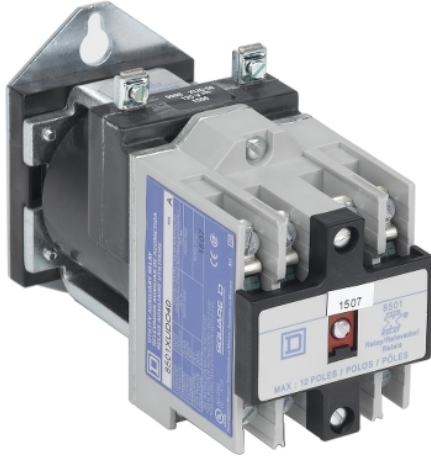

## Main

Range	8501X
Relay Type	Utility
Product	Relay
Current Rating	10 A AC 5 A DC
Contact Configuration	4 NO 4 standard contact cartridges
Number of Poles	4P
Coil Voltage	125 V DC
Voltage Rating	250 V DC
Mounting Type	Panel
Operating Temperature	-40...160 °F (-40...71 °C)
Electrical Connection	Screw clamp terminals
Certifications	UL Listed CE CSA
Operating Time	37 ms - pick-up 21 ms - drop-out
Height	3.56 in (90.42 mm)
Width	2.23 in (56.64 mm)
Depth	5.17 in (131.32 mm)

## Ordering and shipping details

Category	21157 - 8501 XDO (DC)
Discount Schedule	CP2
GTIN	00785901743316
Nbr. of units in pkg.	1
Package weight(Lbs)	3.26 lb(US) (1.48 kg)
Returnability	Yes
Country of origin	MX

## Packing Units

Package 1 Height	21.59 in (54.839 cm)
Package 1 width	8.50 in (21.590 cm)
Package 1 Length	54.84 in (139.290 cm)

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>

---

Environmental Disclosure

[Product Environmental Profile](#)

---

Circularity Profile

[End Of Life Information](#)

---

### Contractual warranty

---

Warranty

18 months

---