

# ASSEMBLY INSTRUCTIONS




## chrome heavy-duty laundry sorter

ITEM # SRT-01235

**DIMENSIONS**

18 in L x 30.75 in W x 32 in H  
(45.7 cm L x 78.1 cm W x 81.3 cm H)

(QTY) DESCRIPTION	PART	ILLUSTRATION	(QTY) DESCRIPTION	PART	ILLUSTRATION
(3) laundry bags	<b>A</b>		(4) casters	<b>D</b>	
(4) support bars	<b>B</b>		(8) screws	<b>E</b>	
(2) side support	<b>C</b>		(8) screw caps	<b>F</b>	
			(1) hex key tool	<b>G</b>	

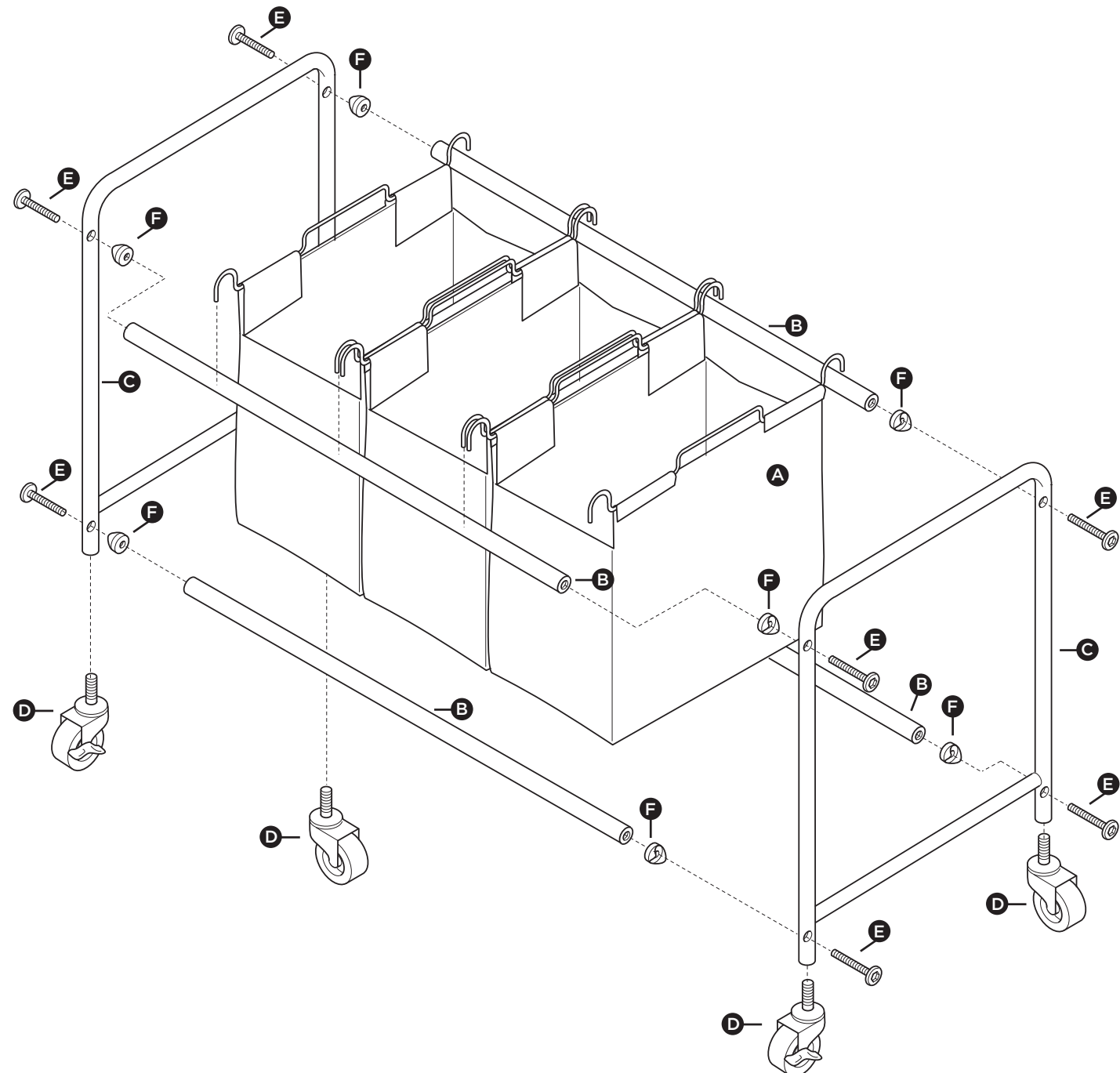

**INSTRUCTIONS**

Thank you for purchasing a Honey-Can-Do Laundry Sorter. Please follow these step-by-step instructions. Please plan to spend about 15 minutes assembling your new sorter. You can do it!

1. Attach all 4 support bars (**B**) into side support (**C**) using 1 screw (**E**) and 1 screw cap (**F**) per bar. To attach a support bar, insert a screw through one of the holes in the side support. Thread the exposed end of the screw (**E**) through the screw cap (**F**), making sure to have the concave end hug the side support (**C**). Secure the support bar (**B**) by threading onto the exposed end of the screw, turning by hand until the support bar is flush against the screw cap (**F**). Tighten using the hex key tool (**G**) until secure.
2. Set the sorter on its side so the exposed ends of the attached support bars (**B**) point up. Attach the remaining side support (**C**) to the support bars (**B**). To attach, line the side support (**C**) up with the attached side support, making sure they

- are pointed in the same direction. Place a screw (**E**) through a hole in the side support (**C**). Thread the exposed end of the screw (**E**) through the screw cap (**F**), making sure to have the concave end hug the side support (**C**). Line up with the support bar (**B**) and use the hex key tool (**G**) to secure the side support to the support bar (**B**)
3. Attach casters (**D**) to the open ends of the side supports (**C**), screwing until tight.
4. Almost done! Hook laundry bags (**A**) onto the support bars (**B**). Enjoy your Honey-Can-Do laundry sorter!

For assistance, please contact us at [info@honeycando.com](mailto:info@honeycando.com) or 877.2.I.Can.Do.

**LIMITED LIFETIME WARRANTY**

This product is warranted to be free of defects in material and workmanship for as long as the consumer owns the product. At Honey-Can-Do's option, defective product will be repaired, replaced or substituted with a product of equal value. For warranty service, e-mail Honey-Can-Do at [warranties@honeycando.com](mailto:warranties@honeycando.com) or call at (877) 242-2636. You may also contact Honey-Can-Do at 5750 McDermott Drive, Berkeley, IL 60163. Do not dispose of the defective item until or unless

you are specifically asked to do so by Honey-Can-Do as we may require return of the defective item. Honey-Can-Do shall in no event be liable for any incidental or consequential damages. Some states do not allow the exclusion or limitation of incidental or consequential damages, so the above exclusion may not apply to you. This warranty gives you specific legal rights, and you may also have other rights, which may vary from state to state.

honey-can-do international

5750 McDermott Drive, Berkeley, IL 60163 USA

tele 877.242.2636

fax 708.240.8198

[www.honeycando.com](http://www.honeycando.com)