


LED DOCK LIGHT

15 watt

50,000 Hours average rated life, 15 Watts, 100V-240V,
660 Focused Lumens, 3 Year Warranty

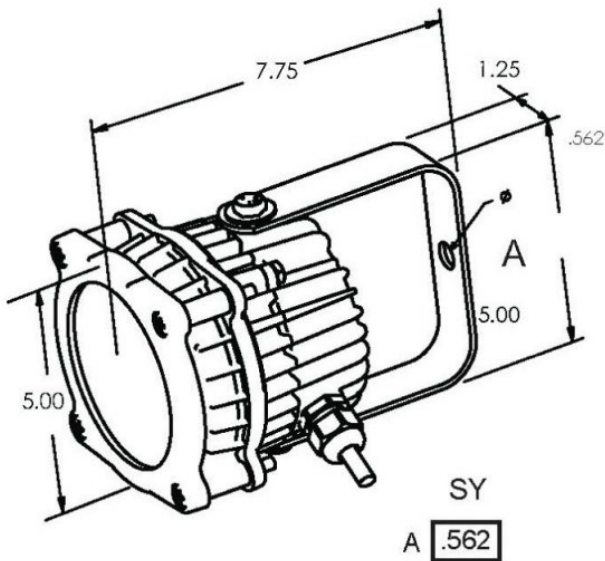

Housing	Die cast aluminum for thermal management
Swivel	Friction joint to allow for 270° angle adjustment
Body	Safety yellow TGIC polyester powder coat paint
Lens	Impact resistant, optically clear acrylic lens with silicone gasket
Fastener	Steel, non-corrosive bright zinc plate
Input Voltage	100-240,277 Volts, 50/60hz
Driver	Constant current electronic driver
Weight	4.8 lbs
Power	15 Watts
CRI	> 0.95
Lifetime	Rated life of 50,000 hours (L70)
UL/IP Rating	Wet locations / IP 65, NEMA3 compliant
Optical System	5 Cree™ high intensity LED emitters with custom focusing options

MOUNTING OPTIONS

Attached to a dock fan



Available as combo package with dockarm

