 


## Echo™ Single Lever Faucet

### FEATURES:

- 1.2 GPM (4.5 L/min) flow rate
- Brass construction
- Lever handle
- Ceramic cartridge
- Inlet supply lines not included, accepts 1/2" NPSM to 3/8" compression supply lines
- Pop-up drain with lift rod
- Corrosion resistant finishes
- Coordinates with Echo Collection

### STOCK FINISHES:



PC BN

### OPTIONS/ADD-ONS:

- -LD : Less Drain
- -BO: 0.5 GPM (1.89 L/min) flow rate
- -GD: with Grid Drain


### STANDARDS:

- ASME A112.18.1/CSA B125.1 certified
- NSF/ANSI 61 certified
- NSF 372 certified
- WaterSense certified
- ADA compliant

### WARRANTY:

Visit [www.speakman.com](http://www.speakman.com) for full product warranty information

- Limited Lifetime Warranty (consumer)
- 5 Year Limited Warranty (commercial)

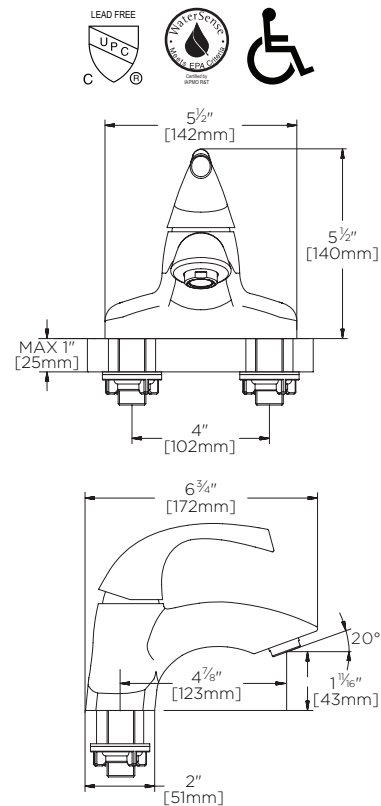

1. All dimensions are in inches (millimeters) unless otherwise specified and are subject to change without notice.

Architect/Engineer Approval Space:

P: 800-537-2107  
 F: 800-977-2747  
 W: WWW.SPEAKMAN.COM  
 R: 04-NOVEMBER 2021W