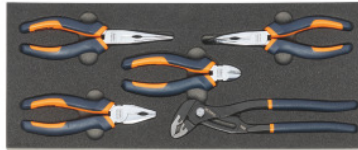


**Garant**
**Pliers set, Number of tools: 5**

**Order data**

Order number	954201 5
GTIN	4062406157456
Item class	91A

**Description**
**Version:**

Popular tool sets in two-colour moulded PE rigid foam inlays. The closed-pore foam is oil-resistant and does not absorb liquids of any sort. Upper layer anthracite, under which the contrast colour of blue indicates if a tool is missing.

The rigid foam inlays fill 1/4 (10 G × 8 G or 250 × 200 mm) or 1/2 (20 G × 8 G or 500 × 200 mm) of the usable drawer area.

**Suitable for:**

**New GARANT roller cabinets** with full extension drawers and a new drawer module of **20 G × 16 G** or 500 × 400 mm (W × D).

**Supplied with:**

GARANT snipe-nose pliers, angled No. 713440 size 200: 1 pc.

GARANT water pump pliers No. 706001 size 250: 1 pc.

GARANT snipe-nose pliers No. 713040 size 200: 1 pc.

Rigid foam inlay, empty No. 952001 size 954201: 1 pc.

GARANT side cutter No. 724840 size 160: 1 pc.

GARANT combination pliers No. 700940 size 180: 1 pc.

Degree of fill of a drawer in units: 8×20

Width: 200 mm

Depth: 500 mm

Width in G: 8

Depth in G: 20

**Technical description**

Width in G	8
Number of tools	5
Width	200 mm
Depth	500 mm
Depth in G	20
Version	with pliers
Weight	1.522 kg
Rigid foam quality LD45, thickness	30 mm
Degree of fill of a drawer in units	8x20
Type of product	Rigid foam inlay

## Accessories

Combination pliers, chrome-plated, with 2-component grips overall length 180 mm	700940 180
Water pump pliers with stepped fine adjustment, black overall length 250 mm	706000 250
Snipe nose pliers, straight, chrome-plated, with grips overall length 200 mm	713040 200
Water pump pliers with stepped fine adjustment, black overall length 250 mm	706001 250
Rigid foam inlay for tool sets suitable for rigid foam set 954201	952001 954201
Diagonal side cutter chrome-plated, with grips overall length 160 mm	724840 160
Snipe nose pliers, angled, chrome-plated, with grips overall length 200 mm	713440 200