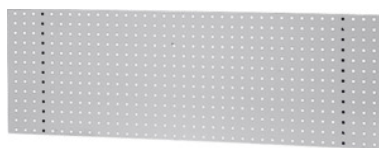


Garant
Perforated panel 481 mm high for wall mounting, Width: 920mm

Order data

Order number	955310 920
GTIN	4062406160180
Item class	91F

Description
NOTE: Colour selection possible
Version:

Stiffened on the back with welded-on channels for wall mounting.

Application:

For direct fixing to walls; after fixing to the wall the fastening screws are not visible. For large wall coverage, perforated panels can be screwed alongside each other and above each other to form a continuous surface.

Supplied with:

Screws and plugs for wall mounting.

Colour:

RAL 7035 light grey **powder coated**.

Colour selection: RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003

Height: 481 mm

Width: 920 mm

Technical description

Height	481 mm
Width	920 mm
Perforated panel version	single-sided
Hoffmann perforated panel grid interval	9×9 mm
Colour selection	RAL 9002, 7035, 7005, 7016, 6011, 5018, 5012, 5011, 5005, 3003

Type of product

Perforated rear panel