


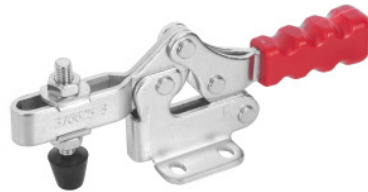

Horizontal toggle clamp with horizontal base, Type: 3



Order data

Order number	376625 3
GTIN	4020772390358
Item class	32S

Description

Version:

Captive contact screws.

With horizontal base for fixing to base plates etc.

Application:

For quick clamping and releasing of parts in series production or for installation as part of special clamping jigs. Suitable for clamping during drilling, reaming, grinding, bending, welding, fitting etc.

Hole spacing e: 26 mm

Hole spacing f: 31.6 mm

Bore Ø d: 6.6 mm

Clamping height H: 33 mm

Clamping force P1: 1650 N

Clamping force P2: 2300 N

Technical description

overall height	68.5 mm
Bore Ø d	6.6 mm
overall length	190 mm
Hole spacing f	31.6 mm
Hole spacing e	26 mm

Clamping force P2	2300 N
Contact screw	M8x50 mm
Clamping force P1	1650 N
Type	376625 3
Clamping height H	33 mm
Type of product	Horizontal toggle clamp