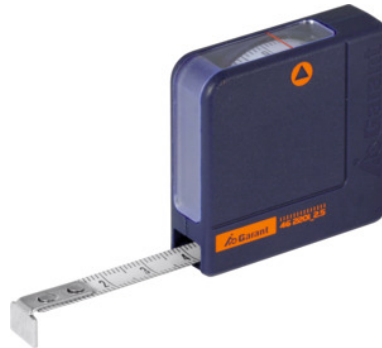


**Garant****Tape measure with viewing window, Band length: 2,5m**

## Order data

Order number	462201 2,5
GTIN	4045197226020
Item class	41H

## Description

### Version:

- **Shock-resistant plastic casing.**
- **Aluminium inlay on both work faces, giving exact contact surfaces for inside and outside measurement.**
- **Aluminium profiles resistant to heat and mechanical loads.**
- **Tape measure stove enamelled, with black characters. Cambered = non-buckling with sliding end hook (for inside and outside measurements). Sharp-contrast, abrasion-resistant rustproof scale.**
- **Graduations mm / mm (upper / lower edges).**
- **Viewing window scale reads in the same direction as the tape.**

Smallest tape measure with viewing window for inside measurements.

Calibration: G1

Standard: EG II

Tape width: 8 mm

Body length: 48 mm

Body width: 15 mm

Body height: 48 mm

## Technical description

Body height	48 mm
Tape width	8 mm
Body length	48 mm
Body width	15 mm
Band length	2.5 m
Standard	EG II
Calibration	G1
Type of product	Measuring tape

## Services

Calibration Locking tape measure maximum length 5 m	016140 5
Labelling laser-etched Type	018940
Calibration Tape measure maximum length 5 m	026240 5
DAkkS Calibration locking tape measure 5	026250 5