

150C/15KVAC,
150C/20KVAC, 150C/25KVAC
150C/30KVAC, and 150C/40KVAC

HI VOLT 3239
HIGH-VOLTAGE LEAD WIRE

RATINGS / APPROVALS

150°C – 15 KVDC - UL Style 3239

150°C – 20 KVDC - UL Style 3239 / CSA TV-20

150°C – 25 KVDC - UL Style 3239

150°C – 30 KVDC - UL Style 3239

150°C – 40 KVDC - UL Style 3239

CONSTRUCTION

Conductors

24 AWG – 10 AWG

Stranded tinned copper

(Other optional conductor materials available)

Insulating System


Extruded silicone rubber

Standard Color Coding

Available in Colors

CHARACTERISTICS

- UL VW-I Flame rated.
- Radiation, ozone, and moisture resistant.
- Easy to strip.
- Very flexible.
- Suitable for applications to -60°C.

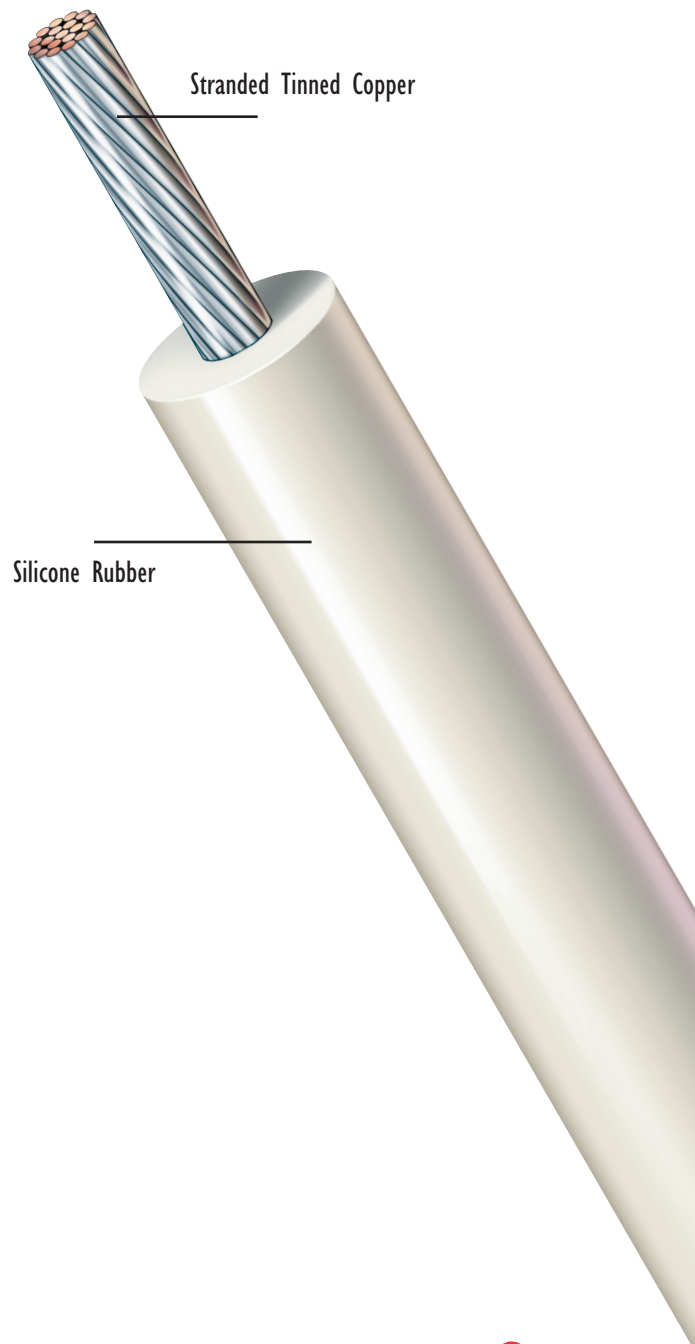

Radix[™]

Radix Wire Company

26000 Lakeland Boulevard • Cleveland, OH 44132

Tel: 216 731-9191 • Fax: 216 731-7082

www.radix-wire.com

SPECIFICATIONS

HI VOLT 3239 HIGH-VOLTAGE LEAD WIRE

HI VOLT 3239 150C/15KVDC

Part No.	Awg. Size	# Strands	Outer Dia. inches	Outer Dia. mm	Wgt - lbs per 1000 ft	Wgt - kg per km	UL	CSA
HOA22T007	22	7	0.124	3.15	7.70	11.46	3239	n/a
HOA20T007	20	7	0.130	3.30	9.36	13.93	3239	n/a
HOA18T016	18	16	0.139	3.53	11.88	17.68	3239	n/a
HOA16T026	16	26	0.149	3.78	15.63	23.26	3239	n/a
HOA14T041	14	41	0.164	4.17	21.37	31.80	3239	n/a
HOA12T065	12	65	0.181	4.60	30.22	44.97	3239	n/a
HOA10T105	10	105	0.204	5.18	44.03	66.52	3239	n/a

HI VOLT 3239 150C/20KVDC

Part No.	Awg. Size	# Strands	Outer Dia. inches	Outer Dia. mm	Wgt - lbs per 1000 ft	Wgt - kg per km	UL	CSA
HPA22T007	22	7	0.124	3.15	8.56	12.74	3239	TV-20
HPA20T007	20	7	0.130	3.30	10.01	14.90	3239	TV-20
HPA18T016	18	16	0.139	3.53	12.59	18.74	3239	TV-20
HPA16T026	16	26	0.149	3.78	16.42	24.44	3239	TV-20
HPA14T041	14	41	0.164	4.17	21.37	31.80	3239	TV-20
HPA12T065	12	65	0.181	4.60	30.22	44.97	3239	TV-20
HPA10T105	10	105	0.204	5.18	44.03	66.52	3239	TV-20

HI VOLT 3239 150C/25KVDC

Part No.	Awg. Size	# Strands	Outer Dia. inches	Outer Dia. mm	Wgt - lbs per 1000 ft	Wgt - kg per km	UL	CSA
HTA22T007	22	7	0.136	3.45	8.90	13.24	3239	n/a
HTA20T007	20	7	0.142	3.61	10.66	15.86	3239	n/a
HTA18T016	18	16	0.151	3.84	13.26	19.73	3239	n/a
HTA16T026	16	26	0.161	4.09	17.11	25.46	3239	n/a
HTA14T041	14	41	0.176	4.47	23.00	34.23	3239	n/a
HTA12T065	12	65	0.193	4.90	32.00	47.62	3239	n/a

HI VOLT 3239 150C/30KVDC

Part No.	Awg. Size	# Strands	Outer Dia. inches	Outer Dia. mm	Wgt - lbs per 1000 ft	Wgt - kg per km	UL	CSA
HQA22T007	22	7	0.142	3.61	9.61	14.30	3239	n/a
HQA20T007	20	7	0.148	3.76	11.35	16.89	3239	n/a
HQA18T016	18	16	0.157	3.99	14.00	20.83	3239	n/a
HQA16T026	16	26	0.167	4.24	17.90	26.64	3239	n/a
HQA14T041	14	41	0.182	4.62	23.85	35.49	3239	n/a
HQA12T065	12	65	0.199	5.05	32.94	49.02	3239	n/a

HI VOLT 3239 150C/40KVDC

Part No.	Awg. Size	# Strands	Outer Dia. inches	Outer Dia. mm	Wgt - lbs per 1000 ft	Wgt - kg per km	UL	CSA
HRA22T007	22	7	0.216	5.49	20.14	29.97	3239	n/a
HRA20T007	20	7	0.222	5.64	22.26	33.13	3239	n/a
HRA18T016	18	16	0.231	5.87	25.41	37.81	3239	n/a
HRA16T026	16	26	0.241	6.12	29.92	44.53	3239	n/a
HRA14T041	14	41	0.256	6.50	36.77	54.72	3239	n/a
HRA12T065	12	65	0.273	6.93	46.86	69.74	3239	n/a
HRA10T105	10	105	0.296	7.52	62.35	92.79	3239	n/a

Contact factory for alternative strandings, sizes and voltages.

All dimensions listed above are nominal.

Compliance: UL Listed File No. E22244 • CSA Certified File No. LL13427 or LL80670

Information included in this catalog is intended as a guideline only. For applications that require tight tolerances, please contact the Radix factory for dimensional verification. Information herein is believed to be accurate as of publication date; however, if an error exists it is unintentional and Radix Wire Company, Inc. is not responsible for any claim traceable to such error.



Radix Wire Company
 26000 Lakeland Boulevard • Cleveland, OH 44132
 Tel: 216 731-9191 • Fax: 216 731-7082
www.radix-wire.com