



»»10' x 20' Heavy Duty Carport

GP Item #: 070018008 - White UPC: 853878007066

GP Item #: 070018009 - Tan UPC: 852443008675

Features:

- 10'8 x 20' | 2" / 48 mm & 1.5" / 38mm Power Coated Steel Frame
- Thumb button locks at fittings for additional stability
- Interchangeable fittings no tools required for assembly
- 180 gram polyethylene cover FR-5 & UV Treatment
- Decorative Leg Skirts at each corner leg
- Large Steel Foot pads
- 9'9" Center Height
- Two Color cover options : white or tan

Box Dimensions & Weight

Box A : 77.5 x 13" x 7.5" - 80.47 lbs.

Box B : 79.9" x 13" x 6.3" 63.93 lbs.

Total Weight : 144.5 lbs

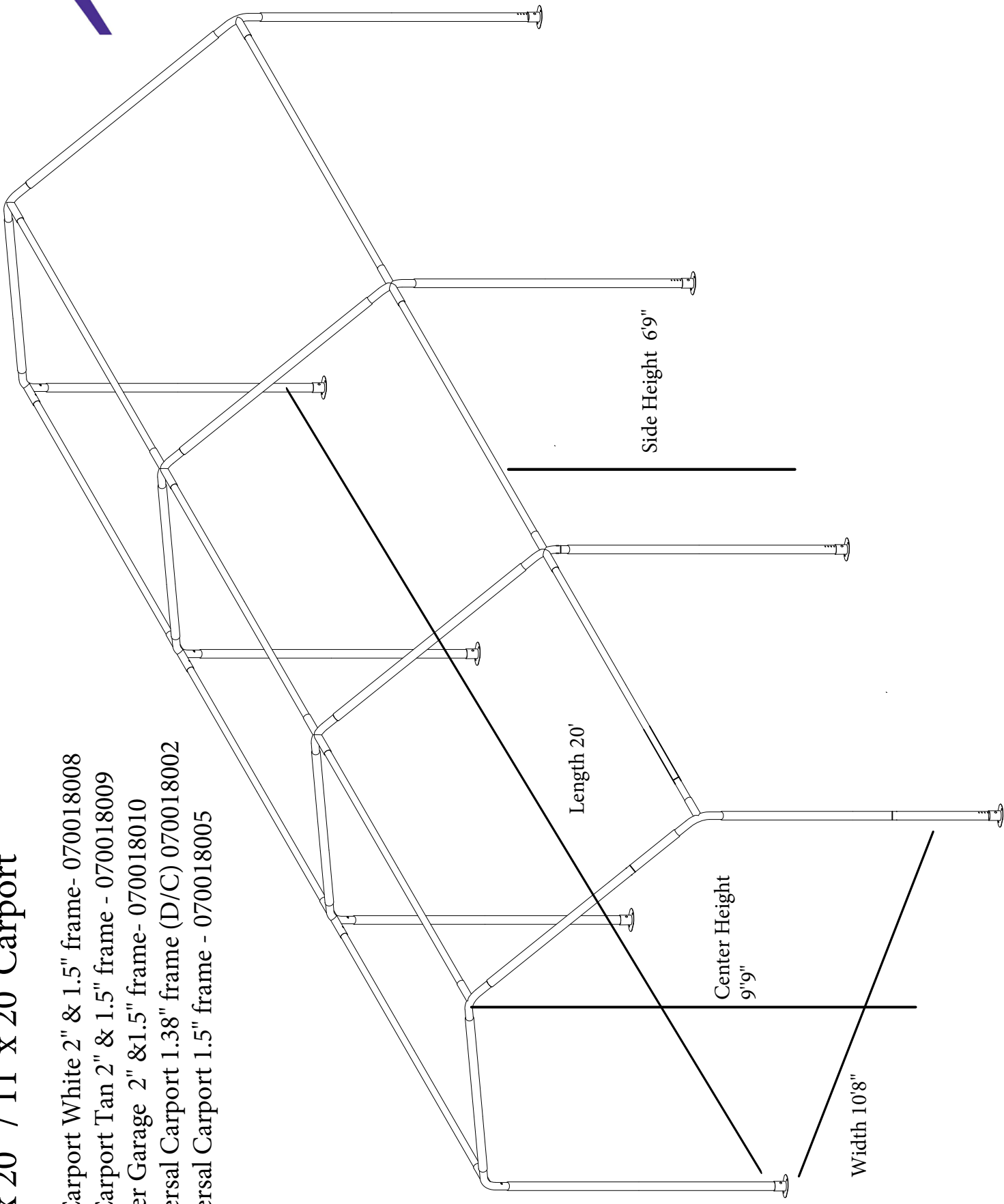
The 10' x 20' Carport offers superior protection from rain, sun and snow with the 14x14 weve 180 gram PE Cover . Great for storing automobiles, tractors, boats or for outdoor shade. No tools required for assembly this heavy grade 2" frame is +8% larger and tall than its competition.



 
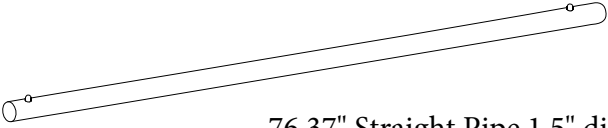
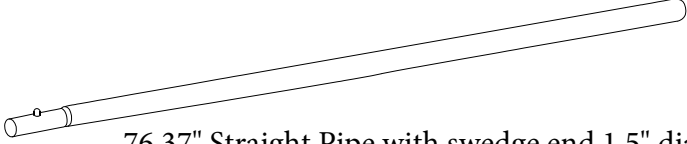
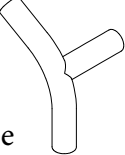
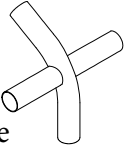

 

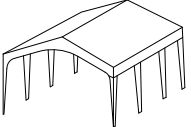
Impact Canopy USA 22600 Temescal Canyon Rd.
Corona, CA 92883 - US: 877.840.3524 x 2043

10' x 20' / 11' x 20' Carport

- HD Carport White 2" & 1.5" frame- 070018008
- HD Carport Tan 2" & 1.5" frame - 070018009
- Winter Garage 2" & 1.5" frame- 070018010
- Universal Carport 1.38" frame (D/C) 070018002
- Universal Carport 1.5" frame - 070018005



-Parts List-

PART	ILLUSTRATION	QUANTITY
A	<p>400701503</p>  <p>61.02" Straight Pipe 1.5" diameter</p>	8
B	<p>400701504</p>  <p>76.37" Straight Pipe 1.5" diameter</p>	9
C	<p>400701505</p>  <p>76.37" Straight Pipe with swedge end 1.5" diameter</p>	8
D	 <p>3 Way fitting for 1.5" diameter pipe</p>	6
E	 <p>4 Way fitting for 1.5" diameter pipe</p>	6
F	 <p>Metal Foot pad for 1.5" diameter pipe</p>	8
G	 <p>Bolt with plastic cap and nut for foot pad</p>	8
H	 <p>Elastic ball bungees white 8"</p>	30
I	<p>070121120</p>  <p>Cover with Leg Skirts</p>	1

