

Low Profile Ground Cords

FGC151M Series


RoHS & REACH Compliant

Low Profile Ground Cords has one banana jack, 10mm male snap, and a 1 Meg resistor. It has a ring type terminal on the other end. These ground cords have a low-profile design and are typically used with ESD Floor Mats.

Product Specifications ⁽¹⁾

Cord Length	15 feet
Type	Straight Cord
Outer Diameter	3mm (+/- 0.1mm)
Wire Insulation	PU/PVC
Resistor	1 Meg Ohm
Color	Black

⁽¹⁾ Specifications are subject to change at any time. If you have any questions, please contact us for the latest update.

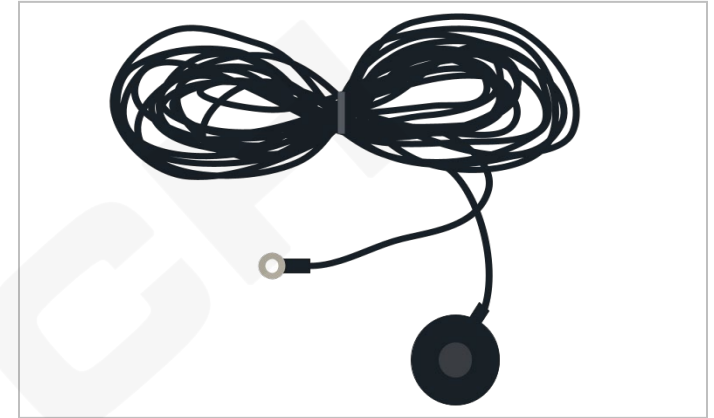

Bertech® makes no warranty, representation, or guarantee regarding the information contained herein or the suitability of its this product for any particular purpose, nor does Bertech® assume any liability whatsoever arising out of the application or use of this product. It is ultimately the responsibility of the customer to determine a product's suitability for a particular application.



Bertech
640 Maple Ave
Torrance, CA 90503
Phone: (310) 787-0337
Email: sales@bertech.com
www.bertech.com

PRODUCT DATA SHEET