



LED EOL-WL13BLK-2050e



Bulkhead Outdoor LED Wall Light W/Matte Black Aluminum Bezel & Ribbed Glass Lens

Product Description

Suitable for commercial and residential spaces, this Euri Lighting LED wall mount provides unbeatable brightness with just 6.2 Watts. Energy efficient and long-lasting, this versatile wall light is designed with grid encasing and a frosted ribbed lens. This oval bulkhead wall mount is available in vibrant and bright Cool White (5000K) and matte black finish. For clean white finish, look for Euri Lighting EOL-WL14WH-2050e.



Estimated Energy Cost: \$0.74 per year

***Note:** Design, features and specifications subject to change without notice. Some features may not be available on all models. For more information please visit: www.eurilighting.com or call 1-888-743-5766

Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
6.2 W	120V/60Hz	434 lm	125°	N/A	5000 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base/Cap	Lamp Lifespan
80	70 lm/W	0.7	0.05 A	Direct Wiring	50,000 Hrs.

Product Features



Non-Dimmable



Instant-On/Off




Mercury Free

 


Wet Rated

Product Dimensions

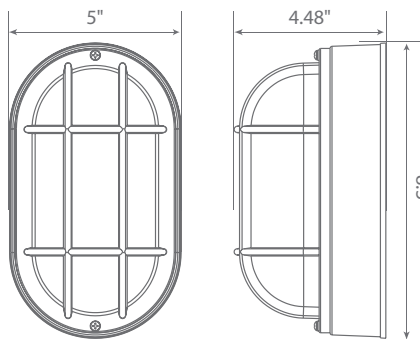

Product Photometric Data



Euri Lighting | A Division of **IRTRONIX** Inc.

20900 Normandie Avenue Bldg. B Torrance, CA 90502 | Tel: 888.743.5766 | Fax: 310.787.1166 | www.eurilighting.com
 ©2018 Euri Lighting. All Rights Reserved