

# LED EP38-20W6021e

Bulb Class: PAR38

**2700K**  
CCT



## Product Description

**LED EP38-20W6021e** delivers superior brightness, valuable energy savings and long lasting performance. This PAR38 LED Long Neck bulb is ideal for ambient lighting or general purpose applications due to its uniform \*warm white light (2700K) and replaces conventional 150 Watt incandescent light bulbs.



**Estimated Energy Cost:** \$2.40 per year

\*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit [www.eurilighting.com](http://www.eurilighting.com) or call 1-310-787-1100 for more information.

## Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
20 W	120V	1700 lm	45°	N/A	2700 K
CRI	Luminous Efficacy	Power Factor	Input Current	Base/Cap	Lamp Lifespan
80	85 lm/W	0.7	0.18 A	E26	25,000 Hrs.

### Product Features



Dimmable




Energy Efficient




Damp Rated

### Product Dimensions

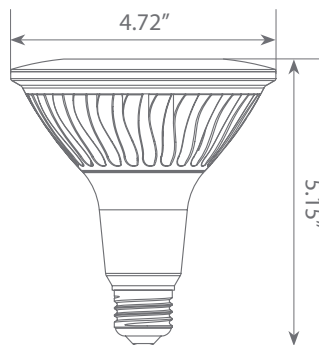

### Product Photometric Data

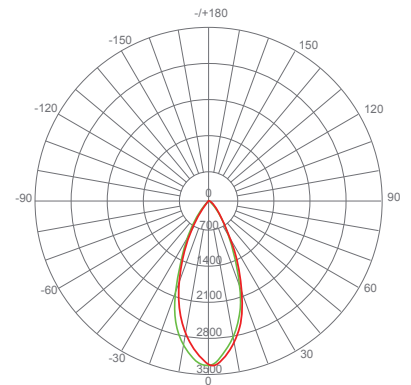

**Euri Lighting | A Division of ITRONIX Inc.**