

LED VA19-3020e

Lamp Class: A19 Clear Glass



Clear Glass



Product Description

LED VA19-3020e delivers superior brightness, valuable energy savings and long lasting performance. LED Filaments along with heat-sink absence unmistakably mimic traditional bulb styles while providing greater light distribution. This A19 Class LED bulb comes in 2700K CCT (*Warm White*) for charming and hospitable environments.



Estimated Energy Cost: \$0.84 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit www.eurilighting.com or call 1-888-743-5766 for more information.

Specifications


Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
7 W	120 V	800 lm	320°	N/A	2700 K

CRI	Luminous Efficacy	Power Factor	Input Current	Base/Cap	Lamp Lifespan
80	114 lm/W	0.7	0.085 A	E26	15,000 Hrs.

Product Features & Benefits

- Dimmable
- Energy Efficient
- Enclosed Fixture Suitable
- Wet Rated

Product Dimensions

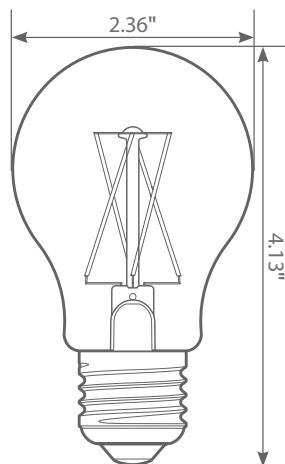

Product Photometric Data

