


LED VBA10-3020ea-4

Lamp Class: BA10 Amber Glass

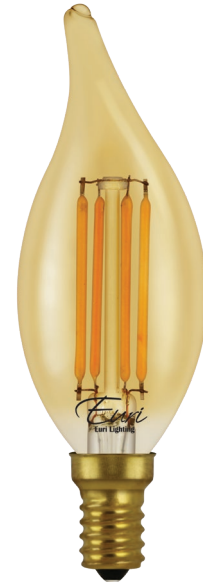

Amber Glass



Product Description

LED VBA10-3020ea-4 delivers superior brightness, valuable energy savings and long lasting performance. LED Filaments along with heat-sink absence unmistakably mimic traditional bulb styles while providing greater light distribution. This BA10 Class LED bulb comes in 2200K CCT (*Warm White*) for charming and hospitable environments.



Estimated Energy Cost: \$0.54 per year

*Note: Design, features and specifications subject to change without notice. Some features may not be available on all models. Please visit www.eurilighting.com or call 1-888-743-5766 for more information.

Specifications

Input Power	Input Voltage	Lumen Output	Beam Angle	Center Beam	CCT
4.5 W	120 V	350 lm	320°	N/A	2200 K

CRI	Luminous Efficacy	Power Factor	Input Current	Base/Cap	Lamp Lifespan
80	77 lm/W	0.7	0.045 A	E12	15,000 Hrs.

Product Features & Benefits



Dimmable



Energy Efficient




Enclosed Fixture Suitable



Wet Rated

Product Dimensions

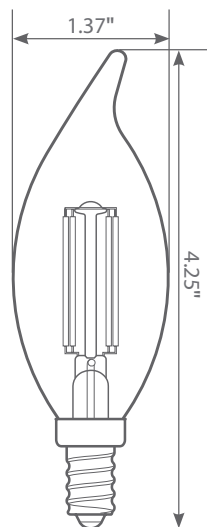

Product Photometric Data

