


# CM405RA-L

8" LED SURFACE MOUNT  
FLUSH MOUNT DISK DOWNLIGHT



Fixture Type
Project
Notes

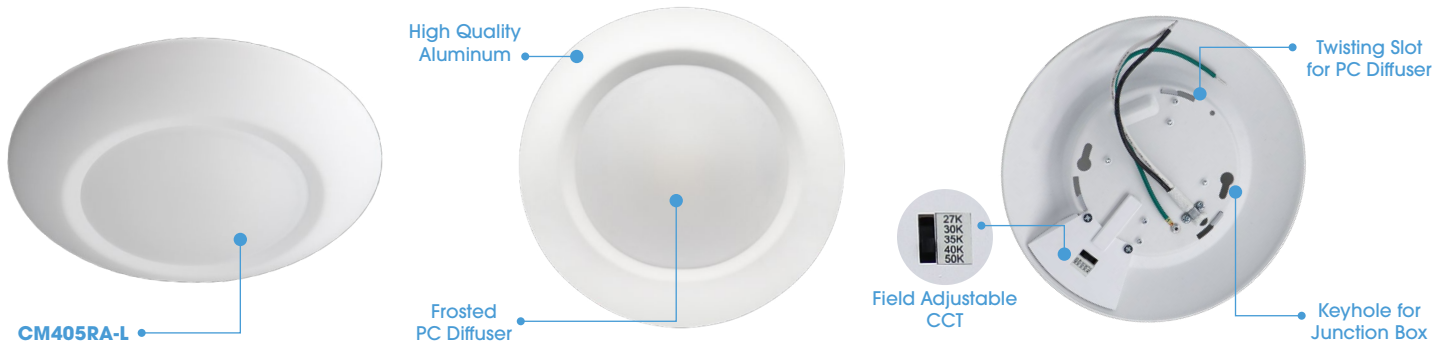

The LED Surface Mount Flush Disk Downlight series is designed for residential and commercial applications. With ultra Low profile design measures a depth of only 1-1/2" and ADA Compliant for Wall Mounting can easily install within a standard junction box or housing. The Frosted Polycarbonate Diffuser provides comfortable non-glare lighting with no hot spots. 5-Level field-selectable Color Temperature and Triac Dimming available.



## SPECIFICATIONS


<b>INPUT VOLTAGE</b>	120V AC
<b>WATTAGE</b>	27 W
<b>LUMENS</b>	2000 Lm
<b>EFFICACY</b>	74 Lm/W
<b>CRI</b>	90+
<b>BEAM ANGLE</b>	120°

<b>DIMMING<sup>1</sup></b>	TRIAC Dimming
<b>ENVIRONMENT</b>	Indoor - Dry & Wet
<b>CERTIFICATIONS</b>	cETLus, T24 Compliant
<b>LUMEN MAINTENANCE</b>	50,000 hours
<b>WARRANTY<sup>2</sup></b>	5 years

<sup>1</sup> Effectively dim down to 10% / See other compatible dimmers on the next page  
<sup>2</sup> See published warranty terms for detailed information

## PERFORMANCE

COLOR TEMPERATURE <sup>3</sup>	LUMEN <sup>4</sup>	WATTAGE	EFFICACY	CRI
SW5 (27/30/35/40/50K) <sup>5</sup>	2000 Lm	27 W	74 Lm/W	90+

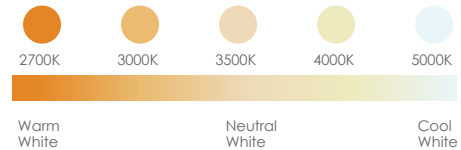

<sup>3 & 4</sup> CCT within +/-10%  
<sup>5</sup> Switchable CCT

## ORDERING INFO



**MODEL**  
**CM405RA-L-SW5-WH**


# CM405RA-L

8" LED SURFACE MOUNT  
FLUSH MOUNT DISK DOWNLIGHT



Fixture Type
Project
Notes


## DIMENSIONAL DRAWINGS

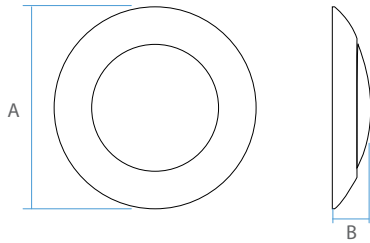

### DIMENSIONS

<b>A</b>	9-1/2"	240 mm
<b>B</b>	1-1/2"	36.8 mm

## INSTALLATION

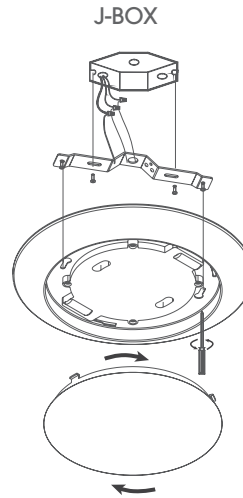

Each Box includes:

- 8" Disk Light
- Mounting brackets
- 2 J-box Screws
- 3 Wire Nuts

## COMPATIBLE DIMMERS

<b>LEVITON</b>	6681, 6672
<b>LUTRON</b>	PD-6WCL, DVCL-153P, CTCL-153P, MACL-153M, TGCL-153P