

# CM408RA-12R

12" ROUND LED SURFACE MOUNT  
WITH SLIM PLASTIC TRIM



Fixture Type
Project
Notes



The LED Surface Mount with Slim Plastic Trim series is designed for residential and commercial applications. The ultra low profile design measures a close-to-ceiling depth of only 7/8". The white translucent acrylic provides comfortable non-glare lighting with no hot spots and instant on. It is ADA Compliant for Wall Mounting and can easily be installed within a standard junction box. With a 3-Level field-selectable Color Temperature can be Triac dimmable.



## SPECIFICATIONS


<b>INPUT VOLTAGE</b>	120V AC
<b>WATTAGE</b>	22 W
<b>LUMENS</b>	1400 Lm
<b>EFFICACY</b>	64 Lm/W
<b>CRI</b>	90+
<b>BEAM ANGLE</b>	120°

<b>DIMMING<sup>1</sup></b>	Triac Dimming
<b>ENVIRONMENT</b>	Indoor - Dry & Wet
<b>CERTIFICATIONS</b>	cETLus, T24 Compliant
<b>LUMEN MAINTENANCE</b>	50,000 hours
<b>WARRANTY<sup>2</sup></b>	5 years

<sup>1</sup> Effectively dim down to 10% / See other compatible dimmers on the next page  
<sup>2</sup> See published warranty terms for detailed information

## PERFORMANCE

COLOR TEMPERATURE <sup>3</sup>	LUMEN <sup>4</sup>	WATTAGE	EFFICACY	CRI
SW3 (30/40/50K) <sup>5</sup>	1400 Lm	22 W	64 Lm/W	90+

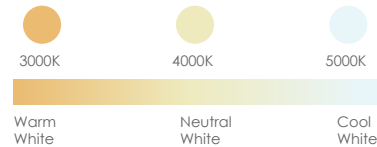

<sup>3&4</sup> CCT within +/-10%  
<sup>5</sup> Switchable CCT

## ORDERING INFO



**MODEL**  
**CM408RA-12R-120V-SW3-WH**



# CM408RA-12R

12" ROUND LED SURFACE MOUNT  
WITH SLIM PLASTIC TRIM



Fixture Type
Project
Notes

## DIMENSIONAL DRAWINGS

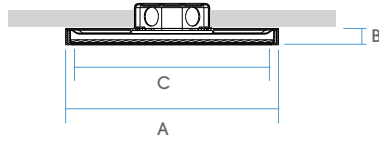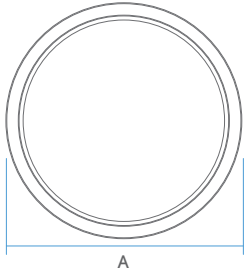


### DIMENSIONS

<b>A</b>	12"	305 mm
<b>B</b>	7/8"	22 mm
<b>C</b>	11"	280 mm

## INSTALLATION

J-BOX

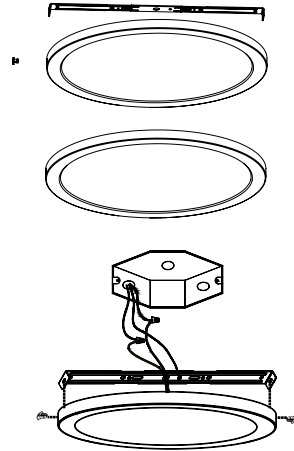

## COMPATIBLE DIMMERS

<b>LEVITON</b>	6681, 6672
<b>LUTRON</b>	PD-6WCL, DVCL-153P, CTCL-153P, MACL-153M, TGCL-153P