

LED DOWNLIGHTS LED SURFACE MOUNTS



THIRD EDITION


JESCO
LIGHTING GROUP

DOWNLIGHTS & SURFACE MOUNTS



JESCO Lighting introduces its next generation of LED Downlights and 120V AC LED Surface Mounts.

With the rapid advancement in LED technology, these fixtures can now produce a greater light output with less wattage, all while providing high color renditions that exceed 90CRI.

This new collection introduces a beautiful Pinhole 1" Micro Downlights with Square and Round Trim options in contemporary finishes as well as a Trimless option that comes with a round mud-in flange. The Pinholes pack a powerful punch, producing 500 lumen of beautiful white light with 7W.

The 2" Miniature Downlights also feature Trimmed and Trimless options. The Trimmed variety includes an interchangeable trim and reflector and offers a selection of Square and Round trims, Pinhole, Wall Wash and Shower Trims in a contemporary matte white and black finishes. The Trimless features square and round mud-in flange options. An adjustable Gimbal version is also available with the Trimmed and Trimless versions.

Also included in this release are the 3", 3.5" and 4" Downlights with integral Square and Round Gimbal, Trimless and Trimmed versions.

The Indirect Edge Lit Downlights feature a hidden light source in a die cast aluminum dome that is engineered to bounce a perfectly soft diffused indirect light. Offered in Square and Round options in white, these fixtures are ultra-shallow in profile and are rated for IC and Airtight.

The Ultra Slim Downlights range from 3" to 8" feature a Square and Round configurations in white, with optional decorative trim rings in Black and other finishes. Ultra-shallow fixtures measure merely 1" in depth.

For greater convenience, all fixtures in these Collections include a plug-and-play remote driver in the same box. Fixtures also feature a 5-level field-selectable color temperature options, from warm 2700K to a cool 5000K, with a high 90+ CRI.

Designed for Commercial and Residential, all fixtures have IC ratings, and most are rated for airtight as well. Most of these fixtures have a very shallow profile, making them perfect for tight spaces.

JESCO Lighting expands and upgrades its popular line of 120V LED CM400 family of Disk Downlights offering to now include 4", 6" and 8" flush mounts with built-in PIR sensors for safety and energy savings. These fixtures feature a 5-level field selectable color temperature, with a high 90+ CRI.

The minimalistic contemporary design Trimless family of Surface Mounts feature a slim white aluminum rim with a frosted PC diffuser that perfectly diffuses bright white light output in warm color temperature options.

Other contemporary ultra-low profile Surface Mounts in this release ranges from 7" to 15", in squares and rounds, with Plastic Trims and Aluminum Diecast Trims, with field selectable color temperatures, and some with PIR sensors.

MICRO RECESSED DOWNLIGHTS



1" Micro Trimmed Downlight
Page 6




1" Micro Trimless Downlight
Page 6

MINIATURE RECESSED DOWNLIGHTS



2" Miniature Trimmed Downlight
Page 8

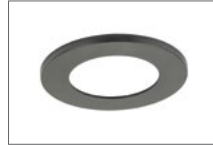

Miniature Trims & Reflectors
Page 10



2" Miniature Trimless Downlight
Page 11

RECESSED DOWNLIGHTS



3" Downlights
Page 14



3.5" & 4" Downlights
Page 14

INDIRECT RETROFIT DOWNLIGHTS



LED Edgelit Indirect Downlights
Page 16

ULTRA SLIM DOWNLIGHTS



3" & 4" LED Ultra Slim Recessed
Page 19



6" & 8" LED Ultra Slim Recessed
Page 20

4" LINE VOLTAGE TRIMLESS RECESSED



4" Line Voltage Recessed
Page 23



4" Line Voltage Recessed Trims
Page 24

CEILING AND WALL SURFACE MOUNTS



Flush Mount Disk Downlight
Page 28



Surface Mount with Trimless Rim
Page 32



Surface Mount with Slim Polycarbonate Trim
Page 35



Surface Mount with Decorative Double Ring Trim
Page 38



Surface Mount with Slim Plastic & Aluminum Trim
Page 36

PRODUCT FEATURES

		MICRO		MINIATURE								RECESSED DOWNLIGHT								INDIRECT						
		RIF-1107 page 7	RIF-1507 page 7	RIF-2108 page 9	RIF-2115 page 9	RIF-2115-UNI page 9	RIF-2708 page 9	RIF-2508 page 11	RIF-2515 page 11	RIF-2515-UNI page 11	RIF-2608-RLT page 11	RIF-3308 page 13	RIF-3408 page 13	RIF-3712 page 13	RIF-3515-RLT page 13	RIF-35312 page 14	RIF-35115 page 14	RIF-4312 page 14	RIF-4412 page 14	RIF-4115 page 15	RIF-4115-UNI page 15	RIF-4515-RLT-UNI page 15	RIF-3112 page 17	RIF-3312 page 17	RIF-5115 page 17	RIF-5315 page 17
SIZE/STYLE	Aperture	1"	1"	2"	2"	2"	2"	2"	2"	2"	3"	3"	3"	3"	3.5"	3.5"	4"	4"	4"	4"	4"	3"	3"	5"	5"	
	New Construction	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	
	Remodel	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	Mounting Plate	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
INPUT	120-277V					●				●											●	●				
	120V	●	●	●	●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		●	●	●	●
RATING	IC-Rated	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	Airtight	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	Damp Locations	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
	Wet Locations	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
LIGHT OUTPUT	LED	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	MR16 GU10 Base																									
	Remote Driver	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	90+ CRI	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	3-CCTs Switch																									
	5-CCTs Switch	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●				
TRIM OPTIONS	Round Trim	●		●	●	●	●				●		●			●	●	●	●	●		●		●		
	Square Trim	●		●	●	●						●			●				●	●			●		●	
	Wall Wash Trim			●	●	●													●	●			●		●	
	Pinhole Trim			●	●	●																				
	Shower Trim			●	●	●																				
	Trimless		●					●	●	●				●								●				
FEATURES	Interchangeable Trims	●	●	●	●	●		●	●	●			●						●	●	●					
	Integrated Trim						●				●	●	●		●	●	●	●				●	●	●	●	
	Interchangeable Reflectors			●	●	●													●	●						
	Selectable Beam Angles																									
	Adjustable After Installed						●				●	●	●		●		●	●								
	Motion Sensor																									
	Emergency Battery																									
	TRIAC Dimming	●	●	●	●		●	●	●	●	●	●	●	●	●	●	●	●	●	●	●		●	●	●	●
	0-10V Dimming					●				●												●	●			

- Applicable
- With optional accessories
- Based on lamp selection

		LED SLIM RECESSED						LINE VOLTAGE		SURFACE MOUNT														
		RLF-3808 page 19	RLF-4812 page 19	RLF-4912 page 19	RLF-6814 page 20	RLF-6914 page 20	RLF-8822 page 20	RS2000ICA-GU10 page 23	RS2000RICA-GU10 page 23	CM405RA-S page 28	CM407RA-S-PIR page 28	CM405RA-M page 29	CM405RA-L page 29	CM407RA-M-PIR page 29	CM404RA-07R page 32	CM404RA-11R page 32	CM408RA-07R page 35	CM408RA-12R page 36	CM409RA-12R page 36	CM409RA-12S page 36	CM409RA-15R page 36	CM403RA-S page 38	CM403RA-M page 38	CM403RA-M-PIR page 38
SIZE/STYLE	Aperture	3"	4"	4"	6"	6"	8"	4"	4"	4"	4"	6"	8"	6"	7"	11"	7"	12"	12"	12"	15"	12"	14"	14"
	New Construction	●	●	●	●	●	●	●	●															
	Remodel	●	●	●	●	●	●		●															
	Mounting Plate	●	●	●	●	●	●																	
INPUT	120-277V																●							
	120V	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
RATING	IC-Rated	●	●	●	●	●	●	●	●															
	IC-Rated Airtight	●	●	●	●	●	●	●	●															
	Damp Locations	●	●	●	●	●	●	●	●													●	●	●
	Wet Locations	●	●	●	●	●	●			●		●	●	●	●	●	●	●	●	●	●			
LIGHT OUTPUT	LED	●	●	●	●	●	●			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	MR16 GU10 Base							●	●															
	Remote Driver	●	●	●	●	●	●																	
	90+ CRI	●	●	●	●	●	●			●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	3-CCTs Switch																●	●	●	●	●			
	5-CCTs Switch	●	●	●	●	●	●			●	●	●	●	●										
TRIM OPTIONS	Round Trim	●	●		●		●																	
	Square Trim			●		●																		
	Wall Wash Trim																							
	Pinhole Trim																							
	Shower Trim																							
	Trimless																							
FEATURES	Interchangeable Trims	●	●	●	●	●	●	●	●															
	Integrated Trim																							
	Interchangeable Reflectors																							
	Selectable Beam Angles																							
	Adjustable After Installed																							
	Motion Sensor										●			●										●
	Emergency Battery																●	●						
	TRIAC Dimming	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●	●
	0-10V Dimming															●								

- Applicable
- With optional accessories
- Based on lamp selection

1" MICRO RECESSED DOWNLIGHTS

RLF-1107

RLF-1507




The 1" Pinhole Micro Downlight packs a powerful punch, producing 500 lumens of beautiful white light with just 7W. Trim options in square and round come in a contemporary matte black and white finish. The Trimless option comes with a round mud-in flange.



FEATURES


- Designed for commercial and residential spaces.
- No housing is required for remodel applications.
- Mounting frame with hanger bars optional for new construction applications.
- 5-level field selectable color temperature.
- TRIAC dimming.
- Wet location rated.
- IC and Airtight rated.
- 5 level field selectable color temperature.

1" MICRO RECESSED DOWNLIGHTS

TYPE	LED MICRO TRIMMED	LED MICRO TRIMLESS		
Model	RLF-1107	RLF-1507		
Description	1" LED Downlight	1" LED Downlight		
Remote Driver Included	●	●		
Aimable				
New Construction	●	●		
Remodel	●	●		
Dimensions	2" Ø × 2 7/8" H	2" Ø × 3 1/2" H		
Ceiling Cutout	2 1/8" Ø	2 1/2" Ø		
Ratings	IC, Airtight	IC, Airtight		
Trim Options Sold Separately	RLT-1101 RLT-1106	Mud-in Flange Included		
Reflector Options Sold Separately				
Input	120V AC	120V AC		
Wattage	7W	7W		
Lumens @3000K	500 Lm	500 Lm		
Efficacy @3000K	71 Lm/W	71 Lm/W		
5 CCT Switchable 2700K, 3000K, 3500K, 4000K, 5000K	●	●		
3000K		●		
CRI	90+	90+		
Beam Angle	30°	38°		
Dimming	TRIAC	TRIAC		
Environment	Indoor - Wet	Indoor - Wet		
Listing	c-ETL-us, Title 24	c-ETL-us, ES, Title 24		
Warranty	5 Years	5 Years		

TRIM OPTIONS

	MODEL/DESCRIPTION	FINISH
	RLT-1101 Round Reflector Trim for RLF-1107	BK - Black WH - White
	RLT-1106 Square Reflector Trim for RLF-1107	BK - Black WH - White

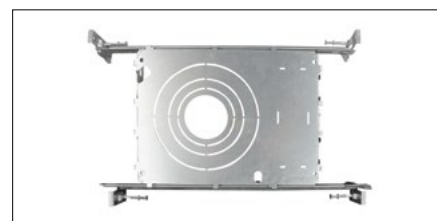

RLH-23354-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 2 1/8"Ø, 2 7/8"Ø, 3 3/4"Ø, 5 1/4"Ø

2" MINIATURE RECESSED DOWNLIGHTS

RLF-2108

RLF-2508



The Miniature Downlights feature 2" Trimmed and Trimless options. The Trimmed variety includes an interchangeable trim and reflector and offers a selection of Square and Round trims, Pinhole, Wall Wash and Shower Trims in a contemporary matte white and black finishes. The Trimless features square and round mud-in flange options. An adjustable Gimbal Downlight option is available with the Trim and Trimless versions.


FEATURES

- Designed for commercial and residential spaces.
- No housing is required for remodel applications.
- Mounting frame with hanger bars optional for new construction applications.
- 5-level field selectable color temperature.
- TRIAC dimming.
- Optional trims in round and square and reflectors in a variety of finishes available for the RLF-2108 and RLF-2115.
- IC and Airtight rated.


2" MINIATURE RECESSED DOWNLIGHTS

TYPE	LED MINIATURE TRIMMED	LED MINIATURE TRIMMED	LED MINIATURE TRIMMED	LED MINIATURE TRIMMED
Model	RLF-2108	RLF-2115	RLF-2115-UNI	RLF-2708
				
Description	2" LED Downlight with Interchangeable Reflector & Round Trim	2" LED Downlight with Interchangeable Reflector & Round Trim	2" LED Downlight with Interchangeable Reflector & Round Trim, Universal Voltage	2" LED Downlight with Gimbal Trim
Remote Driver Included	●	●	●	●
Aimable				30° Tilt, 360° Rotation
New Construction	●	●	●	●
Remodel	●	●	●	●
Dimensions	3 1/8" Ø x 2 7/8" H	3 1/8" Ø x 5" H	3 1/8" Ø x 5" H	3 1/4" Ø x 2" H
Ceiling Cutout	2 7/8" Ø	2 7/8" Ø	2 7/8" Ø	2 7/8" Ø
Ratings	IC Airtight	IC Airtight	IC Airtight	IC
Trim Options Sold Separately	RLT-2101 RLT-2105 RLT-2106 RLT-2109 RLT-2114	RLT-2101 RLT-2105 RLT-2106 RLT-2109 RLT-2114	RLT-2101 RLT-2105 RLT-2106 RLT-2109 RLT-2114	BK - Black WH - White
Reflector Options Sold Separately	RLF-21-REF	RLF-21-REF	RLF-21-REF	
Input	120V AC	120V AC	120-277V AC	120V AC
Wattage	8W	15W	15W	8W
Lumens @3000K	600 Lm	1000 Lm	1000 Lm	600 Lm
Efficacy @3000K	75 Lm/W	67 Lm/W	67 Lm/W	75 Lm/W
5 CCT Switchable 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●	●
CRI	90+	90+	90+	90+
Beam Angle	38°	38°	38°	38°
Dimming	TRIAC	TRIAC	0-10V	TRIAC
Environment	Indoor - Wet*	Indoor - Wet*	Indoor - Wet*	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us
Warranty	5 Years	5 Years	5 Years	5 Years

* With RLT-2109 Trim

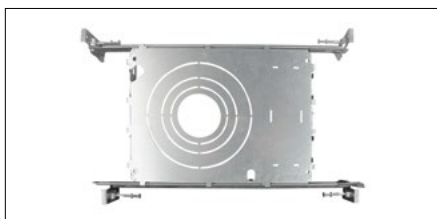

RLH-23354-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 2 1/8"Ø, 2 7/8"Ø, 3 3/4"Ø, 5 1/4"Ø

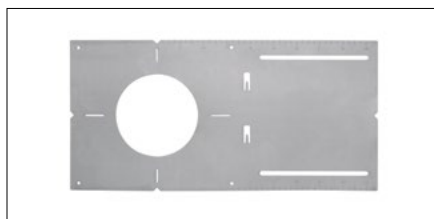







RLH-3334-NC
3" Mounting Plate
Knock out hole size: 13 5/16"Ø, 6 1/2"Ø

2" MINIATURE RECESSED DOWNLIGHTS • TRIMS

REFLECTOR OPTIONS

		MODEL/DESCRIPTION	FINISH
		RLF-21-REF Interchangeable Smooth Reflector for RLF-2108, RLF-2115	BK - Black HZ - Haze



TRIM OPTIONS


		MODEL/DESCRIPTION	FINISH
		RLT-2101 Round Trim for 2" LED Downlight for RLF-2108, RLF-2115 3 1/8" Ø	BK - Black
		RLT-2105 Wall Wash Trim for 2" LED Downlight for RLF-2108, RLF-2115 3 1/8" Ø	WH - White
		RLT-2106 Square Trim for 2" LED Downlight for RLF-2108, RLF-2115 3 1/8" x 3 1/8"	BK - Black WH - White
		RLT-2109 Shower Trim for 2" LED Downlight for RLF-2108, RLF-2115 3 1/8" Ø	WH - White
		RLT-2114 Pinhole Trim for 2" LED Downlight for RLF-2108, RLF-2115 3 1/8" Ø	WH - White

2" MINIATURE TRIMLESS RECESSED DOWNLIGHTS

TYPE	LED MINIATURE TRIMLESS	LED MINIATURE TRIMLESS	LED MINIATURE TRIMLESS	LED MINIATURE TRIMLESS
Model	RLF-2508	RLF-2515	RLF-2515-UNI	RLF-2608-RTL
				
Description	2" LED Trimless Downlight	2" LED Trimless Downlight	2" LED Trimless Downlight, Universal Voltage	2" LED Gimbal Downlight with Mud-In Flange
Remote Driver Included	●	●	●	●
Aimable				30° Tilt, 360° Rotation
New Construction	●	●	●	●
Remodel	●	●	●	●
Dimensions	2 1/2" Ø x 2 1/2" H	2 1/2" Ø x 5" H	2 1/2" Ø x 5" H	3" Ø x 2 1/2" H
Ceiling Cutout	2 7/8" Ø Round 2 7/8" x 2 7/8" Square	2 7/8" Ø Round 2 7/8" x 2 7/8" Square	2 7/8" Ø Round 2 7/8" x 2 7/8" Square	3" Ø
Ratings	IC, Airtight	IC, Airtight	IC, Airtight	IC, Airtight
Mud-in Flange Options Sold Separately	RLT-25-RTL RLT-25-STL	RLT-25-RTL RLT-25-STL	RLT-25-RTL RLT-25-STL	Mud-in Flange Included
Reflector Options Sold Separately				
Input	120V AC	120V AC	120-277V AC	120V AC
Wattage	8W	15W	15W	8W
Lumens @3000K	600 Lm	1000 Lm	1000 Lm	600 Lm
Efficacy @3000K	75 Lm/W	67 Lm/W	67 Lm/W	75 Lm/W
5 CCT Switchable 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●	●
CRI	90+	90+	90+	90+
Beam Angle	38°	38°	38°	38°
Dimming	TRIAC	TRIAC	0-10V	TRIAC
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years	5 Years

TRIM OPTIONS

	MODEL/DESCRIPTION	FINISH
	RLT-25-RTL Round Mud-in Flange for RLF-2508, RLF-2515 2 1/2" A x 3 1/2" Ø	WH - White
	RLT-25-STL Square Mud-in Flange for RLF-2508, RLF-2515 2 1/2" A x 4" x 4"	WH - White

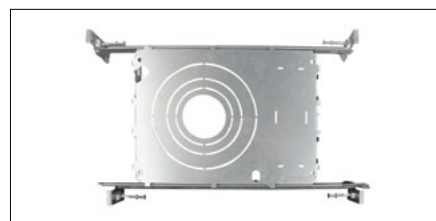

RLH-23354-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 2 1/8"Ø, 2 7/8"Ø, 3 3/4"Ø, 5 1/4"Ø

RLH-346-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 3"Ø, 4 3/8"Ø, 6 1/4"Ø

RECESSED DOWNLIGHTS

RLF-4115



LED Engine

RLF-3515-RLT



LED Engine



Interchangeable Round Reflector Trim



Mud-in Flange



Interchangeable Square Reflector Trim




The 3", 3.5", 4" Recessed Downlight Series feature a variety of integral square and round gimbal and regressed gimbal trims designed for various application needs as well as a modern trimless version.

FEATURES


- Designed for commercial and residential spaces.
- No housing is required for remodel applications.
- Mounting frame with hanger bars optional for new construction applications.
- 5-level field selectable color temperature.
- TRIAC dimming.
- Wet location rated.
- IC and Airtight rated.

3" RECESSED DOWNLIGHTS


TYPE	LED REGRESSED GIMBAL	LED REGRESSED GIMBAL	LED GIMBAL	LED TRIMLESS
Model	RLF-3308	RLF-3408	RLF-3712	RLF-3515-RLT
				
Description	3" Round Regressed Gimbal Downlight	3" Square Regressed Gimbal Downlight	3" Round Gimbal Downlight	3" Round Trimless Downlight
Remote Driver Included	●	●	●	●
Adjustable	30° Tilt, 360° Rotation	30° Tilt, 360° Rotation	30° Tilt, 360° Rotation	
New Construction	●	●	●	●
Remodel	●	●	●	●
Dimensions	4 1/4" Ø x 2 3/8" H	4 1/4" x 4 1/4" x 2 3/8" H	4 7/8" Ø x 2 1/4" H	3" Ø x 2" H
Ceiling Cutout	3 3/8" Ø	3 3/8" Ø	4 1/4" Ø	3 3/4" Ø
Ratings	IC, Airtight	IC, Airtight	IC, Airtight	IC Airtight
Trim Options	BK - Black Integrated Regressed Gimbal WH - White Integrated Regressed Gimbal	BK - Black Integrated Regressed Gimbal WH - White Integrated Regressed Gimbal	BK - Black Integrated Gimbal WH - White Integrated Gimbal	Mud-in Flange Included
Reflector Options <small>Sold Separately</small>				
Input	120V AC	120V AC	120V AC	120V AC
Wattage	8W	8W	12W	15W
Lumens @3000K	600 Lm	600 Lm	800 Lm	1000 Lm
Efficacy @3000K	75 Lm/W	75 Lm/W	67 Lm/W	67 Lm/W
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●	●
CRI	90+	90+	90+	90+
Beam Angle	38°	38°	38°	38°
Dimming	TRIAC	TRIAC	TRIAC	TRIAC
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years	5 Years

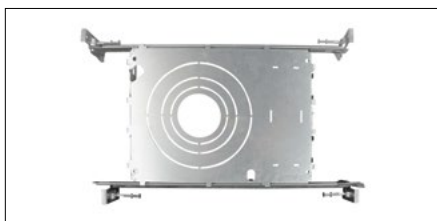

RLH-23354-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 2 1/8"Ø, 2 7/8"Ø, 3 3/4"Ø, 5 1/4"Ø

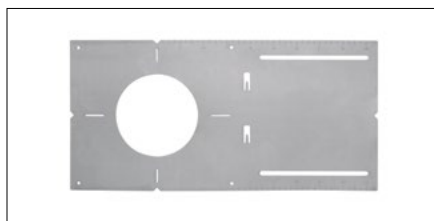



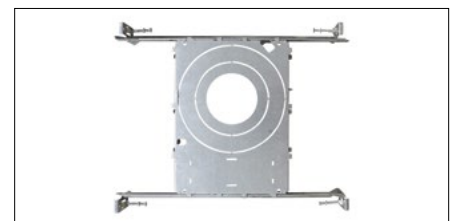


RLH-3334-NC
3" Mounting Plate
Knock out hole size: 3 3/8"Ø




RLH-346-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 3" Ø, 4 3/8" Ø, 6 1/4" Ø

3.5" & 4" RECESSED DOWNLIGHTS


TYPE	LED REGRESSED GIMBAL	LED FIXED TRIM	LED RECESSED GIMBAL	LED REGRESSED GIMBAL
Model	RLF-35312	RLF-35115	RLF-4312	RLF-4412
				
Description	3.5" Round Regressed Gimbal Downlight	3.5" Round Fixed Trim Downlight	4" Round Regressed Gimbal Downlight	4" Square Regressed Gimbal Downlight
Remote Driver Included	●	●	●	●
Adjustable	30° Tilt, 360° Rotation			
New Construction	●	●	●	●
Remodel	●	●	●	●
Dimensions	4 3/8" Ø x 3 1/4" H	4 3/8" Ø x 3 1/4" H	5" Ø x 2 1/2" H	4 7/8" x 4 7/8" x 2 3/8" H
Ceiling Cutout	3 3/4" Ø	3 3/4" Ø	4 1/4" Ø	4 1/4" Ø
Ratings	IC, Airtight			
Trim Options Sold Separately	BK - Black Integrated Regressed Gimbal WH - White Integrated Regressed Gimbal	BK - Black Integrated Fixed Trim WH - White Integrated Fixed Trim	BK - Black Integrated Regressed Gimbal WH - White Integrated Regressed Gimbal	BK - Black Integrated Regressed Gimbal - Square WH - White Integrated Regressed Gimbal - Square
Reflector Options Sold Separately				
Input	120V AC			
Wattage	12W	15W	12W	12W
Lumens @3000K	800 Lm	1000 Lm	800 Lm	800 Lm
Efficacy @3000K	67 Lm/W	67 Lm/W	67 Lm/W	67 Lm/W
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●	●
CRI	90+			
Beam Angle	38°			
Finish	BK - Black WH - White	BK - Black WH - White	BK - Black WH - White	BK - Black WH - White
Dimming	TRIAC			
Environment	Indoor - Wet			
Listing	c-ETL-us, Title 24			
Warranty	5 Years			

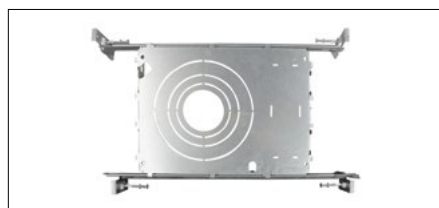



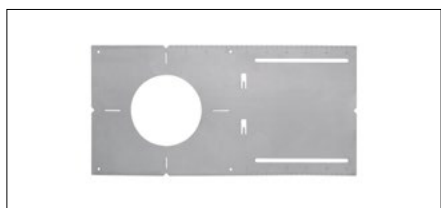

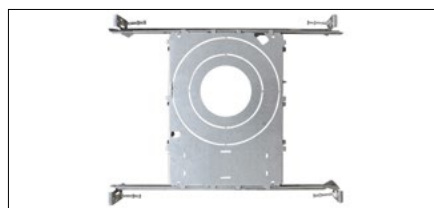

RLH-23354-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 2 1/8"Ø, 2 7/8"Ø, 3 3/4"Ø, 5 1/4"Ø





RLH-3334-NC
3" Mounting Plate
Knock out hole size: 13 5/16"Ø, 6 1/2"Ø



RLH-346-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 3" Ø, 4 3/8"Ø, 6 1/4" Ø

TYPE	LED DOWNLIGHT	LED DOWNLIGHT	LED TRIMLESS
Model	RLF-4115	RLF-4115-UNI	RLF-4515-RTL-UNI
			
			
Description	4" LED Downlight	4" LED Downlight	4" Round Trimless Downlight
Remote Driver Included	●	●	●
Adjustable			
New Construction	●	●	●
Remodel	●	●	●
Dimensions	3 1/8" Ø × 1 7/8" H	3 1/8" Ø × 1 7/8" H	3 5/8" Ø" × 3 1/8" H
Ceiling Cutout	3 3/4" Ø	3 3/4" Ø	3 3/4" Ø
Ratings	IC, Airtight	IC, Airtight	IC Airtight
Trim Options Sold Separately	RLT-4101 RLT-4106	RLT-4101 RLT-4106	Mud-in Flange Included
Reflector Options Sold Separately			
Input	120V AC	120-277V AC	120-277V AC
Wattage	15W	15W	15W
Lumens @3000K	1000 Lm	1000 Lm	1000 Lm
Efficacy @3000K	67 Lm/W	67 Lm/W	67 Lm/W
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●
CRI	90+	90+	90+
Beam Angle	40°	40°	38°
Finish			
Dimming	TRIAC, ELV	0-10V	0-10V
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, ES, Title 24	c-ETL-us, ES, Title 24	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years

TRIM OPTIONS

	MODEL/DESCRIPTION	FINISH
	RLT-4101 4" Interchangeable Round Reflector Trim for RLF-4115 3"Ø A × 4 1/2" Ø	BK - Black WH - White
	RLT-4106 4" Interchangeable Square Reflector Trim for RLF-4115 3"Ø A × 4 1/2" × 4 1/2"	BK - Black WH - White

LED RECESSED INDIRECT DOWNLIGHTS

RLF-5115




DOMES REFLECTOR

The dome reflects a perfectly diffused functional light with no hotspots or glare. The one-piece die cast aluminum dome and heat sink construction provides effective heat dissipation and ensures longevity of LEDs.



INDIRECT LED LIGHT SOURCE

Hidden from view, LEDs are positioned at the edge of the trim pointing up into a dome that reflects a glare-free, soft indirect light.

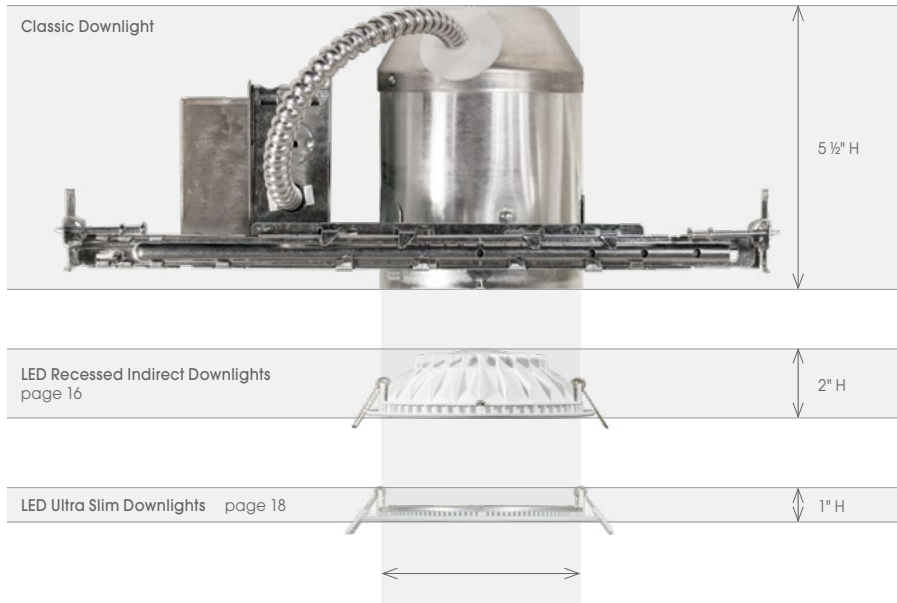





The Indirect Edge Lit Downlights feature a hidden light source in a die cast aluminum dome that is engineered to bounce a perfectly diffused indirect light. Offered in Square and Round options in white, these fixtures are ultra-shallow in profile and are rated for IC and Airtight applications. With an ultra-shallow profile of 2" or less, these fixtures are perfect for tight spaces such as soffits, insulated and suspended ceilings as well as installations directly below ceiling joists. Fixtures install flush to ceiling.


FEATURES

- Designed for commercial and residential spaces.
- No housing is required for remodel applications.
- Mounting frame with hanger bars optional for new construction applications.
- TRIAC dimming.
- IC and Airtight rated.

LED RECESSED INDIRECT DOWNLIGHTS

TYPE	LED EDGELIT INDIRECT	LED EDGELIT INDIRECT	LED EDGELIT INDIRECT	LED EDGELIT INDIRECT
Model	RLF-3112	RLF-3312	RLF-5115	RLF-5315
				
Description	3" Recessed Round Indirect Downlight	3" Recessed Square Indirect Downlight	5" Recessed Round Indirect Downlight	5" Recessed Square Indirect Downlight
Remote Driver Included	●	●	●	●
Adjustable				
New Construction	●	●	●	●
Remodel	●	●	●	●
Dimensions	4 3/4" Ø x 1 1/2" H	4 3/4" x 4 3/4" x 1 1/2" H	6 3/4" Ø x 2" H	6 3/4" x 6 3/4" x 2" H
Ceiling Cutout	4 3/16" Ø	4 3/16" x 4 3/16"	6 3/16" Ø	6 3/16" x 6 3/16"
Ratings	IC, Airtight	IC, Airtight	IC, Airtight	IC, Airtight
Trim Options	WH - Integral White Dome	WH - Integral White Dome	WH - Integral White Dome	WH - Integral White Dome
Input	120V AC	120V AC	120V AC	120V AC
Wattage	12W	12W	15W	15W
Lumens @3000K	660 Lm	620 Lm	1000 Lm	900 Lm
Efficacy @3000K	55 Lm/W	52 Lm/W	67 Lm/W	60 Lm/W
2700K	●	●	●	●
3000K*	●	●	●	●
3500K*	●	●	●	●
4000K*	●	●	●	●
5000K	●	●	●	●
CRI	90+	90+	90+	90+
Beam Angle	110°	110°	110°	110°
Dimming	TRIAC	TRIAC	TRIAC	TRIAC
Environment	Indoor - Dry	Indoor - Dry	Indoor - Dry	Indoor - Dry
Listing	c-ETL-us, Title 24*	c-ETL-us, Title 24*	c-ETL-us, Title 24*	c-ETL-us, Title 24*
Warranty	5 Years	5 Years	5 Years	5 Years


* All models - 3000K, 3500K, 4000K are Title 24 JA8 compliant
 ● Consult Factory

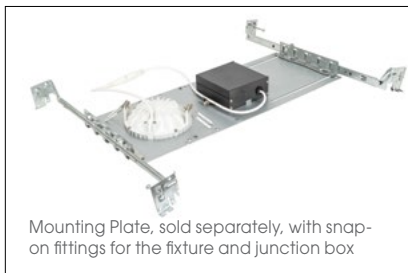

Mounting Plate, sold separately, with snap-on fittings for the fixture and junction box

RLF-31F
 New Construction
 Mounting Plate for RLF-3112


RLF-51F
 New Construction
 Mounting Plate for RLF-5115

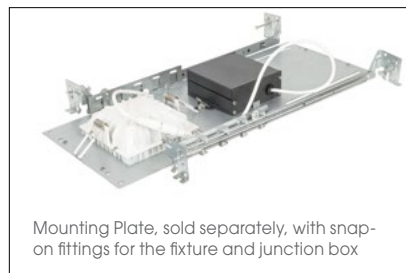

Mounting Plate, sold separately, with snap-on fittings for the fixture and junction box

RLF-33F
 New Construction
 Mounting Plate for RLF-3312

RLF-53F
 New Construction
 Mounting Plate for RLF-5315

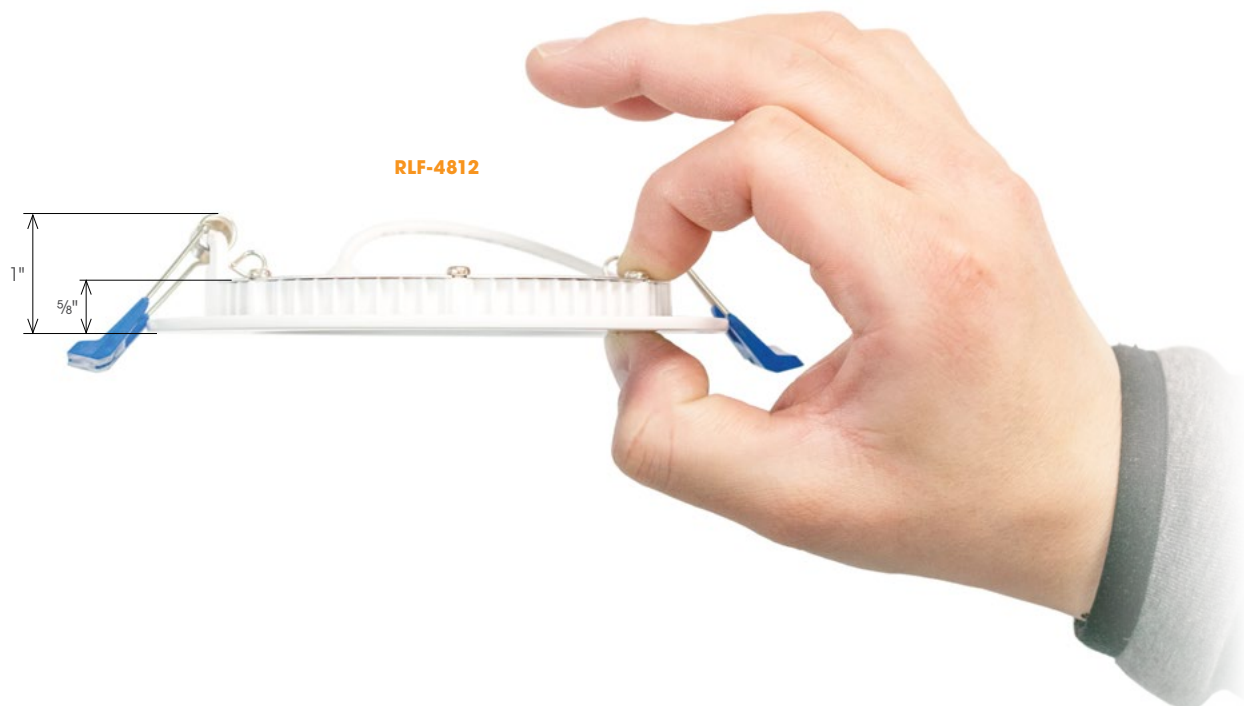




The Ultra Slim Downlight Series ranges from 3" to 8", features a square and round configuration in white, with optional decorative trim rings in black and other finishes.

With an ultra-shallow profile of merely 1" deep coupled with IC Airtight rating, this Slim Downlight is perfect for tight spaces such as soffits, insulated and suspended ceilings.




FEATURES


- Designed for residential and commercial spaces.
- No housing is required for remodel applications.
- Mounting frame with hanger bars optional for new construction applications.
- TRIAC dimming.
- IC and Airtight rated.
- Optional decorative trim rings available.
- 5 level field selectable color temperature.

3" & 4" LED ULTRA SLIM DOWNLIGHTS

TYPE	LED ULTRA SLIM	LED ULTRA SLIM	LED ULTRA SLIM
Model	RLF-3808	RLF-4812	RLF-4912
			
Description	3" Ultra Slim Downlight with Round White Trim	4" Ultra Slim Downlight with Round White Trim	4" Ultra Slim Downlight with Square White Trim
Remote Driver Included	●	●	●
New Construction	●	●	●
Remodel	●	●	●
Dimensions	3 3/4" Ø x 1" H	5" Ø x 1" H	4 5/8" x 4 5/8" x 1" H
Ceiling Cutout	3" Ø	4 1/4" Ø	4 1/4" Ø
Ratings	IC, Airtight	IC, Airtight	IC, Airtight
Trim Options Sold Separately	RLT-38	RLT-48	RLT-49
Input	120V AC	120V AC	120V AC
Wattage	8W	12W	12W
Lumens @3000K	500 Lm	800 Lm	800 Lm
Efficacy @3000K	63 Lm/W	67 Lm/W	67 Lm/W
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●
3000K		●	
CRI	90+	90+	90+
Beam Angle	120°	120°	120°
Dimming	TRIAC	TRIAC	TRIAC
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years




TRIM OPTIONS

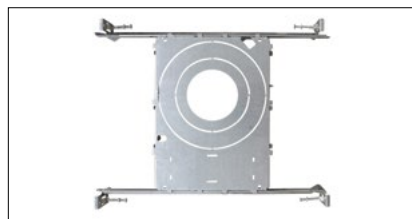	MODEL/DESCRIPTION	FINISH
	RLT-38 3" Round Decorative Trim Ring for RLF-3808	BK - Black BN - Brushed Nickel
	RLT-48 4" Round Decorative Trim Ring for RLF-4812	BK - Black BN - Brushed Nickel BZ - Oil Rubbed Bronze
	RLT-49 4" Square Decorative Trim Ring for RLF-4912	BK - Black BN - Brushed Nickel




RLH-346-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 3" Ø, 4 5/8" Ø, 6 1/4" Ø

6" & 8" LED ULTRA SLIM DOWNLIGHTS

TYPE	LED ULTRA SLIM	LED ULTRA SLIM	LED ULTRA SLIM
Model	RLF-6814	RLF-6914	RLF-8822
			
Description	6" Ultra Slim Downlight with Round White Trim	6" Ultra Slim Downlight with Square White Trim	8" Ultra Slim Downlight with Round White Trim
Remote Driver Included	●	●	●
New Construction	●	●	●
Remodel	●	●	●
Dimensions	6 7/8" Ø x 1" H	6 7/8" x 6 7/8" x 1" H	9" Ø x 1" H
Ceiling Cutout	6 1/4" Ø	6 1/4" Ø	8 1/4" Ø
Ratings	IC, Airtight	IC, Airtight	IC, Airtight
Trim Options Sold Separately	RLT-68	RLT-69	
Input	120V AC	120V AC	120V AC
Wattage	14W	14W	22W
Lumens @3000K	900 Lm	900 Lm	1600 Lm
Efficacy @3000K	64 Lm/W	64 Lm/W	73 Lm/W
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	●	●	●
3000K	●		
CRI	90+	90+	90+
Beam Angle	120°	120°	120°
Dimming	TRIAC	TRIAC	TRIAC
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years

TRIM OPTIONS

	MODEL/DESCRIPTION	FINISH
	RLT-68 6" Round Decorative Trim Ring for RLF-6814	BK - Black BN - Brushed Nickel
	RLT-69 6" Square Decorative Trim Ring for RLF-6914	BK - Black BN - Brushed Nickel

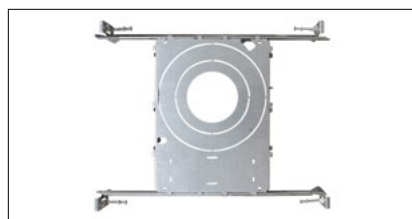

RLH-346-NC-UNI
Universal Mounting Plate with Hanger Bars
Knock out hole size: 3" Ø, 4 3/8" Ø, 6 1/4" Ø



4" LINE VOLTAGE RECESSED

New INFINA® Ultra High Output in Frosted. INFINA incorporates a driverless AC LED technology enclosed in a frosted thermoplastic jacket, allowing for long runs without the need for remote power supplies. Without drivers, the weakest link in the LED system is eliminated, guaranteeing longevity, lowering upfront installation and maintenance costs. Dimmable with an electronic low voltage controller.



Although integrated LED is the leading source for downlights today, LED GU10 lamps are still prevalent in applications where clients are not ready to make the switch.

Our 4" Line Voltage Recessed Downlight offering includes an IC and Airtight rated New Construction and Remodeling Housing, with a variety of trim options for every residential application.

FEATURES

- IC housing may be covered with insulation for energy conservation.
- Airtight rated.
- Junction box is supplied with ½" knockouts.
- Housings available in both 4" New Construction and Remodel.

TYPE	GU10 DOWNLIGHT	GU10 DOWNLIGHT		
Model	RS2000ICA-GU10	RS2000RICA-GU10		
Description	4" Line Voltage New Construction Housing	4" Line Voltage Remodel Housing		
New Construction	●			
Remodel		●		
Dimensions	8" L x 5 1/2" W x 5 1/2" H	12" L x 4 1/2" W x 5 1/2" H		
Ceiling Cutout	4 1/4" Ø	4 1/4" Ø		
Ratings	IC, Airtight	IC, Airtight		
Trim Options Sold Separately	See page 24	See page 24		
Input	120V AC	120V AC		
Wattage	12W Max	12W Max		
Lamp Type	MR16 GU10	MR16 GU10		
Dimming	See lamp specs	See lamp specs		
Environment	Indoor - Damp	Indoor - Damp		
Listing	c-ETL-us	c-ETL-us		
Warranty	5 Years	5 Years		

LED LAMPS RETROFIT OPTIONS




 











LL-MR16GU10-6W-38-2780
LL-MR16GU10-6W-38-3080
LL-MR16GU10-6W-38-4080
COB LED 120V AC GU10 MR16 LAMP
 Input: 120V AC
 Watts: 6W (40W equivalent)
 Base: GU10
 Beam: 35°
 CCT: 2700K, 3000K, 4000K
 CRI: 80+
 Lumen: 450 Lm @3000K
 Dimming: ELV
 Dimensions: 2" Ø x 2.20" H



LL-MR16GU10-7HW-40-2780
LL-MR16GU10-7HW-40-3080
LL-MR16GU10-7HW-40-4080
LED 120V AC GU10 MR16 LAMP
 Input: 120V AC
 Watts: 7.5W (50W equivalent)
 Base: GU10
 Beam: 35°
 CCT: 2700K, 3000K, 4000K
 CRI: 80+
 Lumen: 650 Lm @3000K
 Dimming: ELV
 Dimensions: 2" Ø x 2.20" H

4" LINE VOLTAGE RECESSED • TRIMS

TRIM OPTIONS

	MODEL/DESCRIPTION	FINISH
	TM215-RTL-GU10 4" Round Mud-in Flange	WH - White BK - Black
	TM215-STL-GU10 4" Square Mud-in Flange	WH - White BK - Black
	TM401 Adjustable Step Baffle 3 1/2" A x 5" Ø Vertical Adj: 15°	WHWH - White
	TM402 Adjustable Open Reflector 3 1/2" A x 5" Ø Vertical Adj: 15°	CHBK - Chrome / Black CHCH - Chrome CHWH - Chrome / White PBWH - Polished Brass / White STST - Satin Chrome WHWH - White
	TM403 Adjustable 2-piece Oval Slot Aperture with Black Interior 2 1/8" A x 5" Ø Vertical Adj: 35°	ST - Satin Chrome
	TM404 Wall Washer with Step Baffle 3 1/2" A x 5" Ø x 1/4" Ext	WHWH - White
	TM405 Adjustable Eyeball with Step Baffle 2" A x 5" Ø x 1 3/8" Ext Vertical Adj: 35°	AB - Antique Bronze WH - White
	TM408 Adjustable Gimbal Ring 1 5/8" A x 4 7/8" Ø x 5/8" Ext Vertical Adj: 30°	AB - Antique Bronze ST - Satin Chrome WH - White
	TM409 Flat Shower Trim with Frosted Glass Wet Location 3 5/8" A x 5" Ø	BK - Black ST - Satin Chrome WH - White
	TM410 Dropped Shower Trim with Opal Glass Wet Location 3 1/2" A x 5" Ø x 1" Ext	WH - White
	TM411 Die Cast Aluminum Adjustable Periscope 1 1/4" A x 5" Ø x 2 1/2" Ext Vertical Adj: 80°	AB - Antique Bronze BK - Black CH - Chrome ST - Satin Chrome
	TM412 Shower Trim with Albalite Glass Wet Location 3 5/8" A x 4 1/2" Ø	AB - Antique Bronze ST - Satin Chrome WH - White
	TM426 Adjustable Gimbal Ring with Step Baffle 2" A x 5" Ø x 5/8" Ext Vertical Adj: 30°	AB - Antique Bronze BK BK - Black WHWH - White





CM405RA-M



CM407RA-M-PIR



Frosted PC Diffuser

PIR Sensor

5 CCT Switch



5 CCT Switch




The Disk Downlights Series now includes 4", 6" and 8" flush mounts with built-in PIR sensors for safety and energy savings. These fixtures feature a 5-level field selectable color temperature with a high 90+ CRI. CM407 is rated for Closet use.

FEATURES

- Designed for Residential and Commercial applications.
- Ultra Low profile design.
- ADA Compliant for Wall Mounting.
- Frosted Polycarbonate Diffuser provides comfortable non-glare lighting with no hot spots.
- Easily installs within a standard junction box.
- 5-Level field-selectable Color Temperature.
- TRIAC Dimming.
- CM407 is rated for Closet use.




4" CEILING AND WALL • SURFACE MOUNTS

TYPE	LED SURFACE MOUNT	LED SURFACE MOUNT		
Model	CM405RA-S	CM407RA-S-PIR		
				
Description	4" Flush Mount Disk Downlight	4" Flush Mount Disk Downlight with PIR Sensor		
Ceiling Mount	•	•		
Wall Mount	•	•		
Motion Detector		•		
Dimensions	6 1/8" Ø x 1 1/4" H	6 7/8" Ø x 1 1/4" H		
Finish	WH - White	WH - White		
Input	120V AC	120V AC		
Wattage	10W	10W		
Lumens @3000K	600 Lm	600 Lm		
Efficacy @3000K	60 Lm/W	60 Lm/W		
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	•	•		
CRI	90+	90+		
Beam Angle	120°	120°		
Dimming	TRIAC			
Environment	Indoor - Wet	Indoor - Wet		
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24, Closet Rating NEC Sec. 410.16 (A)(3) & 410.16 (C)(5)		
Warranty	5 Years	5 Years		



CM405S-MK
Adapters for 3" Junction Box

6" & 8" CEILING AND WALL • SURFACE MOUNTS

TYPE	LED SURFACE MOUNT	LED SURFACE MOUNT	LED SURFACE MOUNT
Model	CM405RA-M	CM407RA-M-PIR	CM405RA-L
			
Description	6" Flush Mount Disk Downlight	6" Flush Mount Disk Downlight with PIR Sensor	8" Flush Mount Disk Downlight
Ceiling Mount	•	•	•
Wall Mount	•	•	•
Motion Detector		•	
Dimensions	7 3/8" Ø x 1 3/8"H	7 3/4" Ø x 1 1/4" H	9 1/2" Ø x 1 1/2"H
Finish	WH - White BN - Brushed Nickel *	WH - White	WH - White
Input	120V AC	120V AC	120V AC
Wattage	15W	15W	27W
Lumens @3000K	900 Lm	1000 Lm	2000 Lm
Efficacy @3000K	60 Lm/W	67 Lm/W	74 Lm/W
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	•	•	•
3000K	•		
CRI	90+	90+	90+
Beam Angle	120°	120°	120°
Dimming	TRIAC		TRIAC
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24, Closest Rating NEC Sec. 410.16 (A)(3) & 410.16 (C)(5)	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years

* CM405RA-M-3090 only



CM405M-MK
Mounting Clip and E26 Socket Adapter
Includes: Mounting Clip,
E26 Adapter






The minimalistic contemporary design Trimless family of Surface Mounts feature a slim white aluminum rim with a frosted PC diffuser that perfectly diffuses bright white light output in warm color temperature options.

FEATURES

- Designed for Residential and Commercial applications.
- Minimalistic contemporary design with a trimless aluminum rim in white finish.
- Frosted polycarbonate perfectly diffuses bright white light.
- Ultra Low Profile unit measures merely 3/4" deep.
- ADA Compliant for Wall Mounting
- Installs easily in a standard junction box.
- TRIAC Dimming.

CEILING AND WALL • SURFACE MOUNTS

TYPE	LED SURFACE MOUNT	LED SURFACE MOUNT		
Model	CM404RA-07R	CM404RA-11R		
Description	7" Surface Mount with Trimless Rim	11" Surface Mount with Trimless Rim		
Ceiling Mount	●	●		
Wall Mount	●	●		
Dimensions	7" Ø x ¾"H	11" Ø x ¾"H		
Finish	WH - White	WH - White		
Input	120V AC	120V AC		
Wattage	15W	20W		
Lumens @3000K	1000 Lm	1500 Lm		
Efficacy @3000K	67 Lm/W	75 Lm/W		
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K				
3000K	●	●		
3500K		●		
CRI	90+	90+		
Beam Angle	120°	120°		
Dimming	TRIAC	TRIAC		
Environment	Indoor - Wet	Indoor - Wet		
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24		
Warranty	5 Years	5 Years		



CM404-MK
Mounting Clip and E26 Socket Adapter
Includes: Mounting Clip,
E26 Adapter



CM408RA-07R-120V




Contemporary ultra-low profile Surface Mounts in this release ranges from 7" to 15", in squares and rounds, with Plastic Trims and Aluminum Diecast Trims, with field selectable color temperatures, and some with PIR sensors.

FEATURES

- Designed for commercial and residential spaces.
- Ultra Low profile design measures a close-to-ceiling depth of only $\frac{7}{8}$ " - 1".
- ADA Compliant for Wall Mounting
- Instant on.
- White translucent acrylic provides comfortable non-glare lighting with no hot spots.
- Easily installs within a standard junction box.
- 3-Level field-selectable Color Temperature.
- TRIAC dimming

7" CEILING AND WALL • SURFACE MOUNTS

TYPE	LED SURFACE MOUNT	LED SURFACE MOUNT		
Model	CM408RA-07R-120V	CM408RA-07R-UNI		
Description	7" Surface Mount with Slim Polycarbonate Trim	7" Universal Voltage Surface Mount with Slim Polycarbonate Trim		
Ceiling Mount	•	•		
Wall Mount	•	•		
Optional EM Battery	•			
Dimensions	7 7/8" Ø x 5/8" H	7 7/8" Ø x 5/8" H		
Finish	WH - White	WH - White		
Input	120V AC	120-277V AC		
Wattage	15W	15W		
Lumens @3000K	900 Lm	900 Lm		
Efficacy @3000K	60 Lm/W	60 Lm/W		
5 CCT Switch 2700K, 3000K, 3500K, 4000K, 5000K	•			
3000K		•		
CRI	90+	90+		
Beam Angle	120°	120°		
Dimming	TRIAC	0-10V		
Environment	Indoor - Wet	Indoor - Wet		
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24		
Warranty	5 Years	5 Years		



CM408RA-07R-EM-WH





Optional Emergency Battery Backup for CM408RA-07R
Lithium battery backup module
Input: 120V, 60Hz, 0.2A Max.
Power: 15W
Recharge Time: 24 hours
Operating Time: 90 min.
Dimensions: 7 7/8" Ø x 1" H



CM408RA-07R-MP-WH

Optional Mounting Plate To match the depth of a CM408 with Emergency Battery Backup installed within the same space, the CM408RA-07R-MP-WH can be attached to the back of a standard fixture.
Dimensions: 7 7/8" Ø x 1" H

12" & 15" CEILING AND WALL • SURFACE MOUNTS

TYPE	LED SURFACE MOUNT	LED SURFACE MOUNT	LED SURFACE MOUNT	LED SURFACE MOUNT
Model	CM408RA-12R-120V	CM409RA-12R-120V	CM409RA-12S-120V	CM409RA-15R-120V
				
Description	12" Round Surface Mount with Slim Plastic Trim	12" Round Surface Mount with slim Aluminum Die Cast Trim	12" Square Surface Mount with slim Aluminum Die Cast Trim	15" Round Surface Mount with slim Aluminum Die Cast Trim
Ceiling Mount	•	•	•	•
Wall Mount	•	•	•	•
Optional EM Battery				
Dimensions	12" Ø x 7/8"H	12" Ø x 1"H	12" x 12" x 1"H	15" Ø x 1"H
Finish	WH - White	WH - White	WH - White	WH - White
Input	120V AC	120 AC	120V AC	120V AC
Wattage	22W	22W	22W	30W
Lumens @3000K	1400 Lm	1400 Lm	1450 Lm	2000 Lm
Efficacy @3000K	64 Lm/W	64 Lm/W	66 Lm/W	67 Lm/W
3 CCT Switch 3000K, 3500K, 5000K	•	•	•	•
CRI	90+	90+	90+	90+
Beam Angle	120°	120°	120°	120°
Dimming	TRIAC	TRIAC	TRIAC	TRIAC
Environment	Indoor - Wet	Indoor - Wet	Indoor - Wet	Indoor - Wet
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24
Warranty	5 Years	5 Years	5 Years	5 Years

CM403RA-M

Decorative Brushed Nickel Double Ring Trim



Frosted PC Diffuser


PIR Sensor option is available



Decorative brushed nickel double ring trim with frosted PC diffuser is available in a 12" and 14" size and with PIR sensor.

FEATURES

- Designed for commercial and residential spaces.
- Features a contemporary double ring steel trimming in Brushed Nickel.
- Close-to-Ceiling design.
- Ultra Low Profile unit measures merely ¾" deep.
- ADA compliant for Wall Mounting.
- Frosted Polycarbonate Diffuser provides comfortable non-glare lighting with no hot spots.
- Built-in Driver.
- Simple installation.
- TRIAC dimming.

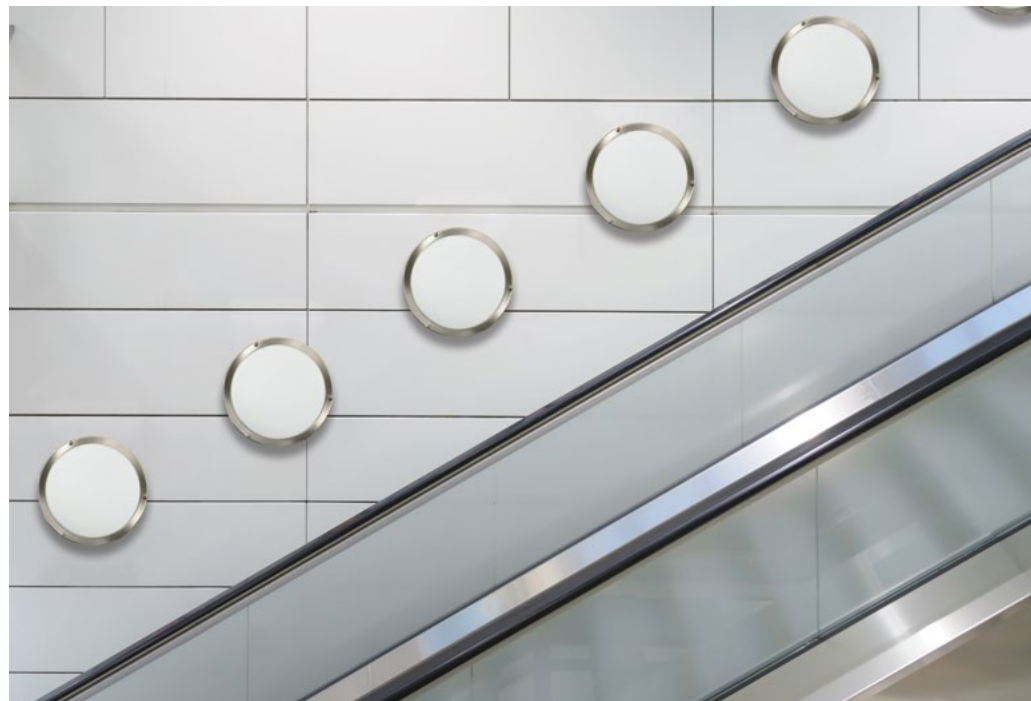

CEILING AND WALL • SURFACE MOUNTS

TYPE	LED SURFACE MOUNT	LED SURFACE MOUNT	LED SURFACE MOUNT	
Model	CM403RA-S	CM403RA-M	CM403RA-M-PIR	
				
Description	12" Surface Mount with Decorative Double Ring Trim	14" Surface Mount with Decorative Double Ring Trim	14" Surface Mount with Decorative Double Ring Trim with Sensor	
Ceiling Mount	•	•	•	
Wall Mount	•	•	•	
Motion Detector			•	
Dimensions	12" Ø x 3 3/4" H	14 3/4" Ø x 4 3/4" H	14 3/4" Ø x 4 3/4" H	
Finish	BN - Brushed Nickel	BN - Brushed Nickel	BN - Brushed Nickel	
Input	120V AC	120V AC	120V AC	
Wattage	15W	18W	18W	
Lumens @3000K	900 Lm	1200 Lm	1200 Lm	
Efficacy @3000K	60 Lm/W	67 Lm/W	67 Lm/W	
3000K	•	•	•	
4000K	•	•		
CRI	90+	90+	90+	
Beam Angle	120°	120°	120°	
Dimming	TRIAC	TRIAC		
Environment	Indoor - Damp	Indoor - Damp	Indoor - Damp	
Listing	c-ETL-us, Title 24	c-ETL-us, Title 24	c-ETL-us, Title 24	
Warranty	5 Years	5 Years	5 Years	

C

CM403A-M. 38
 CM403A-M-PIR 38
 CM403RA-S 38
 CM404-MK. 32
 CM404RA-07R 32
 CM404RA-11R 32
 CM405M-MK 29
 CM405RA-L 29
 CM405RA-M 29
 CM405RA-S 28
 CM405S-MK 28
 CM407RA-M-PIR 29
 CM407RA-S-PIR 28
 CM408RA-07R-120V 35
 CM408RA-07R-EM-WH 35
 CM408RA-07R-MP-WH 35
 CM408RA-07R-UNI 35
 CM408RA-12R-120V 36
 CM409RA-12R-120V 36
 CM409RA-12S-120V 36
 CM409RA-15R-120V 36

L

LL-MR16GU10-6W-38-2780 23
 LL-MR16GU10-6W-38-3080 23
 LL-MR16GU10-6W-38-4080 23
 LL-MR16GU10-7HW-40-2780 23
 LL-MR16GU10-7HW-40-3080 23
 LL-MR16GU10-7HW-40-4080 23


R

RLF-21-REF 10
 RLF-31F 17
 RLF-33F 17
 RLF-51F 17
 RLF-53F 17
 RLF-1107 7
 RLF-1507 7
 RLF-2108 9
 RLF-2115 9
 RLF-2115-UNI. 9
 RLF-2508 11
 RLF-2515 11
 RLF-2515-UNI 11
 RLF-2608-RTL 11

RLF-2708 9
 RLF-3112 17
 RLF-3308 13
 RLF-3312 17
 RLF-3408 13
 RLF-3515-RLT. 13
 RLF-3712 13
 RLF-3808 19
 RLF-4115 15
 RLF-4115-UNI. 15
 RLF-4312 14
 RLF-4412 14
 RLF-4515-RLT-UNI 15
 RLF-4812 19
 RLF-4912-SW5 19
 RLF-5115 17
 RLF-5315 17
 RLF-6814 20
 RLF-6914 20
 RLF-8822 20
 RLF-35115 14
 RLF-35312 14
 RLH-346-NC-UNI 11 13 14 19 20
 RLH-3334-NC 9 13 14
 RLH-23354-NC-UNI 7 9 11 13 14
 RLT-25-RTL 11
 RLT-25-STL 11
 RLT-38 19
 RLT-48 19
 RLT-49 19
 RLT-68 20
 RLT-69 20
 RLT-1101 7
 RLT-1106 7
 RLT-2101 10
 RLT-2105 10
 RLT-2106 10
 RLT-2109 10
 RLT-2114 10
 RLT-4101 15
 RLT-4106 15
 RS2000ICA-GU10 23
 RS2000RICA-GU10 23

T

TM215-RTL-GU10 24
 TM215-STL-GU10 24
 TM401 24
 TM402 24
 TM403 24
 TM404 24
 TM405 24
 TM408 24
 TM409 24
 TM410 24
 TM411 24
 TM412 24
 TM426 24

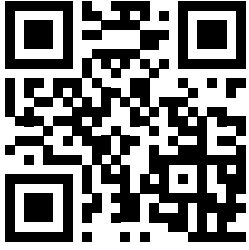

For more details and product specifications please visit JESCOLIGHTING.COM



NEW YORK
CORPORATE OFFICE
15 Harbor Park Drive
Port Washington NY 11050
TEL 800 527 7796
FAX 855 265 5768

LOS ANGELES
219 South 6th Avenue
City of Industry CA 91746
TEL 800 527 7796
TEL 626 333 3661

JESCOLIGHTING.COM
info@jescolighting.com

© 2023 JESCO Lighting

LCAT-DL-SM-V3-2023

