


L562

LED TRACKHEAD

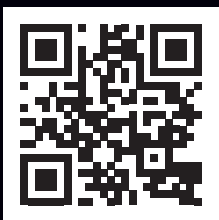



L562 S

LED	12W	1000 Lm	83 Lm/W	90+ CRI	DIM
15°	24°	40°	90°	330°	ETL

Dims: 2 1/2" Ø × 7 1/2" L (63.5 mm × 191 mm)

L562 M

LED	22W	2000 Lm	91 Lm/W	90+ CRI	DIM
15°	24°	38°	90°	330°	ETL

Dims: 3 1/4" Ø × 7 1/2" L (81.5 mm × 191 mm)

L562 L

LED	36W	3000 Lm	83 Lm/W	90+ CRI	DIM
15°	24°	38°	90°	330°	ETL

Dims: 3 13/16" Ø × 8 1/2" L (96.5 mm × 216 mm)

Dimming: TRIAC

Environment: Indoor - Dry

LED Life: 50,000 hr

FEATURES

- Cylindrical design in three sizes, the L562 Series is constructed of diecast aluminum with no exposed wiring.
- Offered in black and white powder-coated finishes
- High output LED COB delivers 1000 Lm, 2000 Lm and 3000 Lm on the Small, Medium and Large fixtures respectively.
- 3-step MacAdam LED for color consistency from fixture to fixture, ensuring uniformity within a space.
- Fixtures rotate 330° with a 90° tilt for precision aiming.
- Interchangeable optics in 15°, 24°, 38°** and 40°*.
- Single and dual circuit H, L, J track system options.

TO ORDER

SYSTEM	MODEL	CCT/CRI	BEAM	FINISH
J2 - J Track ¹	L562 S	2790 - 2700K 90CRI	15D - 15°	BK - Black
H2 - H Track ²	L562 M	3090 - 3000K 90CRI	24D - 24°	WH - White
L2 - L Track ³	L562 L	4090 - 4000K 90CRI	38D - 38°**	
		5090 - 5000K 90CRI	40D - 40°*	

* L562S only

** L562L and L562M only

¹ JESCO J, J1, J2 Track or Juno Track-Master. Juno is registered Trademark of Juno Lighting.

² JESCO H, H1 Track or Halo Power-Track. Halo is registered Trademark of Cooper Lighting.

³ JESCO L Track or Lightolier Lytespan Track. Lightolier is registered Trademark of Philips Lighting.

Specifications subject to change without notice. See spec sheet or jescolighting.com for more details.

