


36" BRECKENRIDGE VANITY

JAMES MARTIN
VANITIES™

330-V36-LNO

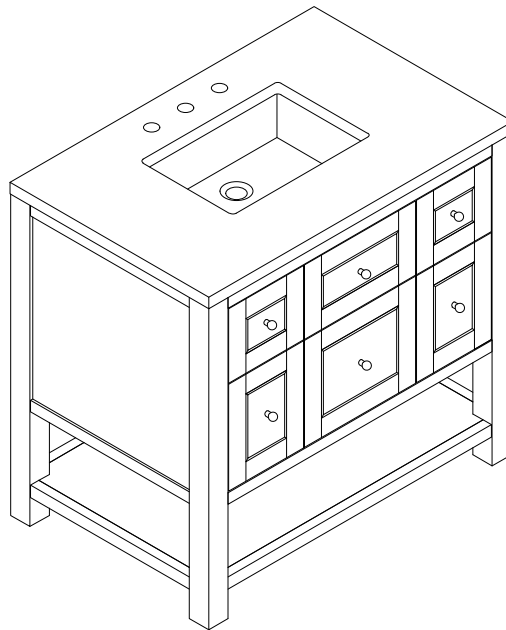

Features

Materials

Solids (Species): Ash

Veneers: Flat Cut White Oak

Panels: Plywood

Number of Basins: Single

Vanity Top : Sold Separately - 3cm Top with Sink

Basins Included: No

Number of Doors: One

Number of Drawers: Two

Number of Tip Outs: Two

USB/Power Component:Yes (ETL5011080)

Assembly Required: No

Bamboo Storage Tray: No

Drawer Box Material and Construction: 12mm Plywood/English Dovetail Joinery

Hardware Material and Finish: Zinc Alloy in Matte Black

Fits Drain Hole Size: 1-3/4"

Full Extension, Soft Close Glides

European Soft Close Hinges

Aluminum Laminate Drawer Liners

Dimension

Width:35-7/8"

Depth:23-1/2"

Height:33"

Rough-In Height:21-1/2"



Visit website for warranty and installation information
www.jamesmartinvanities.com

Version:202211


36" BRECKENRIDGE VANITY



330-V36-LNO

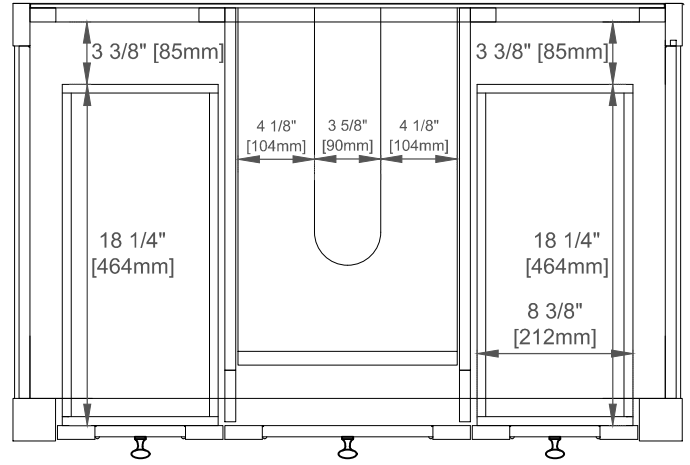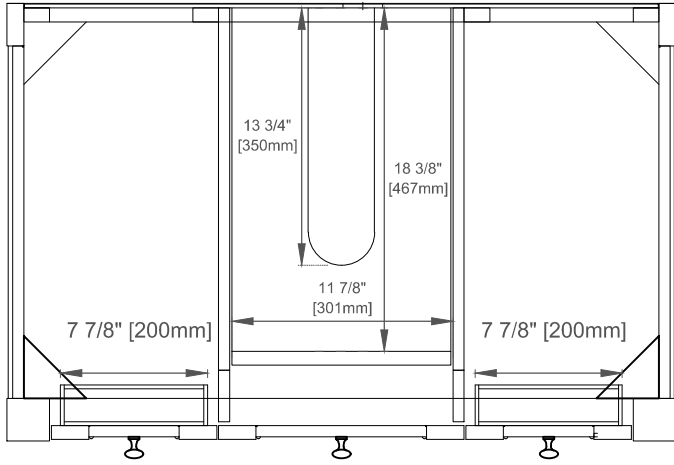

Top View

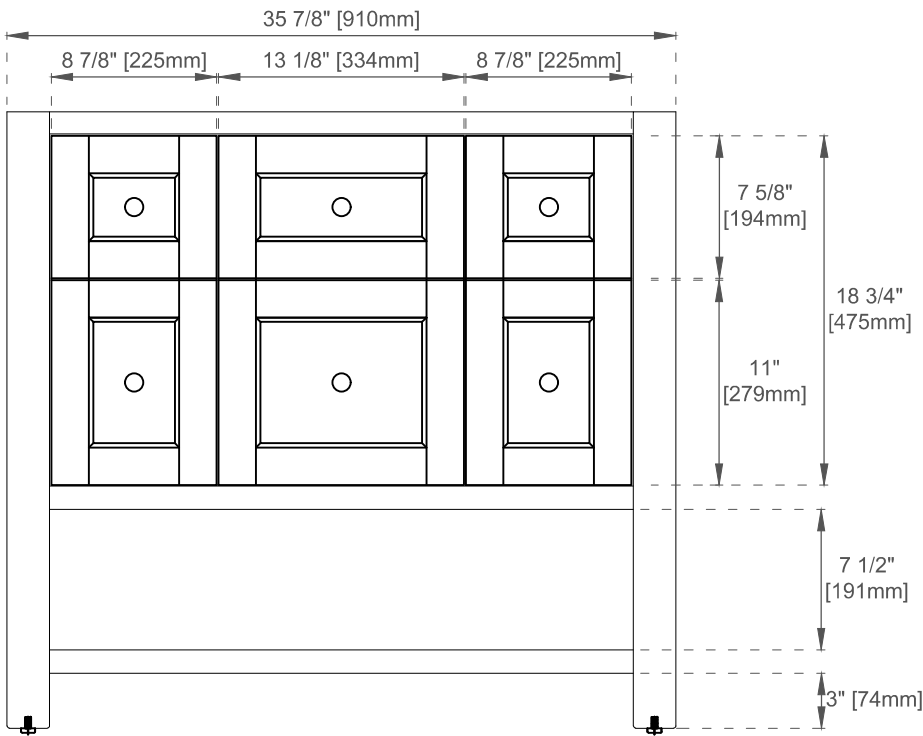

Front View


Diagrams are of cabinets only –James Martin Optional Countertops and sinks are not shown

Visit website for warranty and installation information
www.jamesmartinvanities.com


36" BRECKENRIDGE VANITY



330-V36-LNO

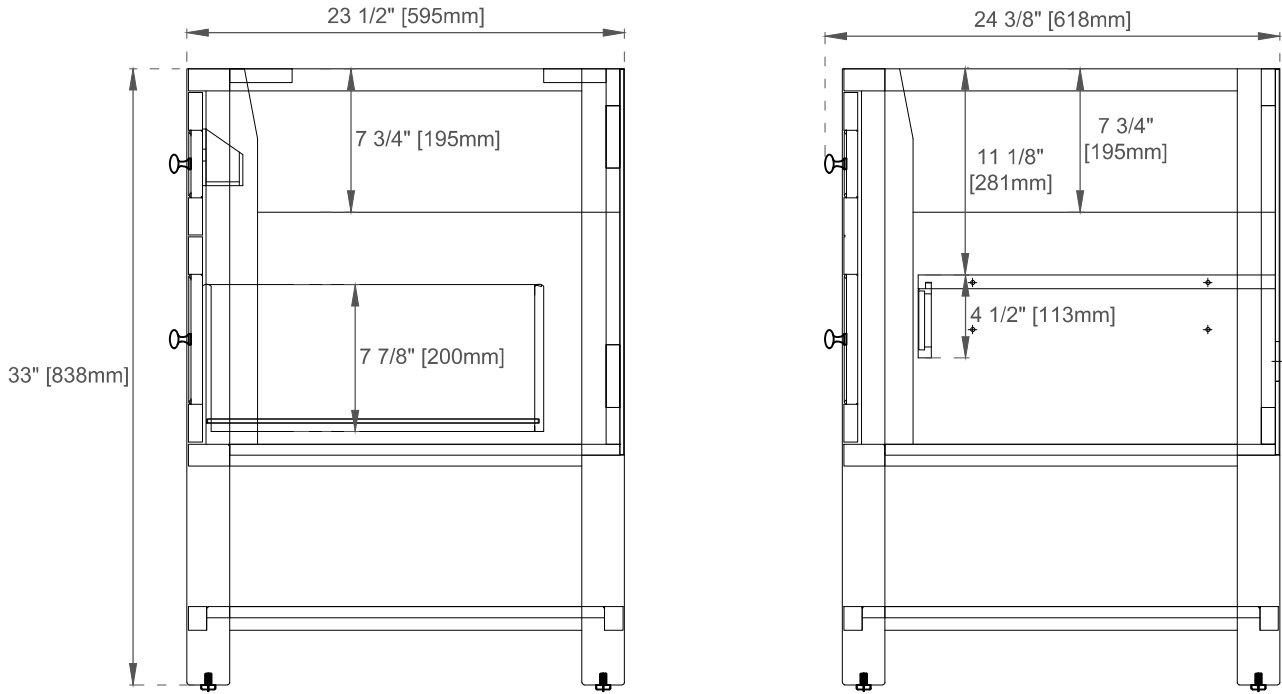

Side View

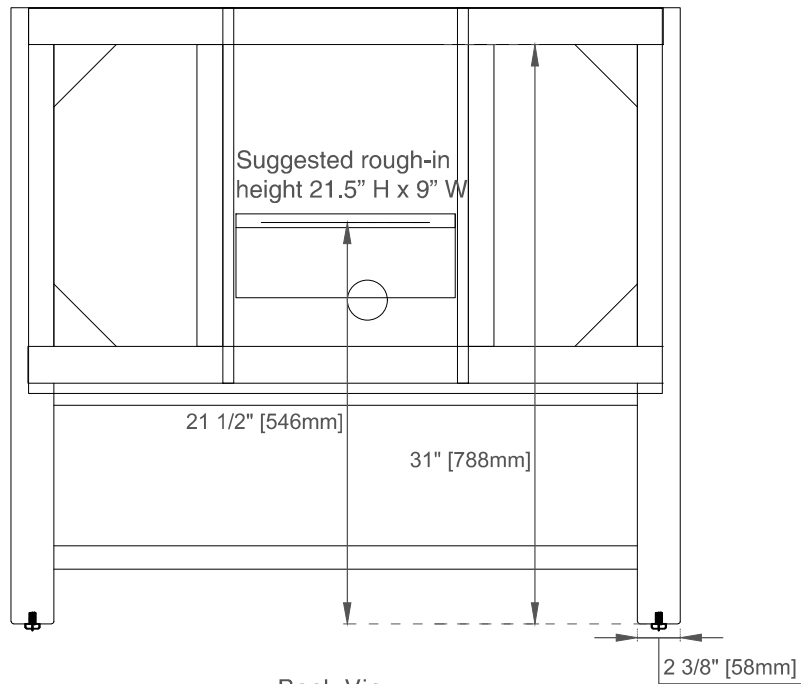

Back View

Diagrams are of cabinets only –James Martin Optional Countertops and sinks are not shown

Visit website for warranty and installation information
www.jamesmartinvanities.com