


Style: **ACCESS**

Hand shower – Douche à main

FINISH	Polished chrome
TYPE OF JETS	Spray
NUMBER OF POSITIONS	1
MAXIMUM FLOW RATE	9.5 L/min (2.5 gpm) at 80 psi
HAND SHOWER DIMENSIONS	1-3/4" x 9-1/2"
COMPOSITION	Polymer
CONNECTIONS	1/2" IPS
SPECIFICATIONS	Easy-to-clean soft nozzles Built-in check valves

FINI	Chrome poli
TYPE DE JETS	Diffus
NOMBRE DE POSITIONS	1
DÉBIT MAXIMAL	9,5 L/min (2,5 gpm) à 80 psi
DIMENSIONS DOUCHE À MAIN	1-3/4" x 9-1/2"
COMPOSITION	Polymère
CONNEXIONS	1/2 po IPS
SPÉCIFICITÉS	Buses souples faciles à nettoyer Soupapes anti-retour intégrées

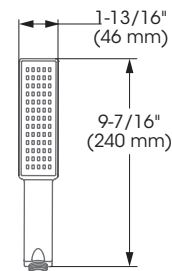

This product is covered by a limited lifetime warranty. Consult our website for complete details.

Ce produit est couvert par une garantie à vie limitée. Consultez notre site internet pour tous les détails.



Bélanger follows cUPC certification standards for shower components.

Bélanger respecte les normes de certification cUPC pour ses composantes de douche.