

Product Image




U-Bolts

U-bolts are manufactured from low carbon steel and feature NC rolled threads that are intended to be installed through pre-drilled holes for supporting conduit from strut. They are also ideal for attaching pipe, conduit, or other cylindrical materials. They come furnished with hex nuts and straps.

Features:

- Low carbon steel
- NC rolled threads
- Zinc plated
- Hex nuts & plate included

Product Dimensions

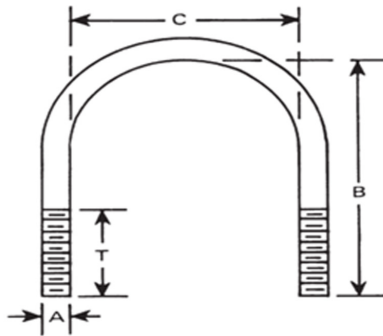

PN	Diameter & Thread	ID 'C'	Inside Length 'B'	Thread Length 'T'
U50	1/4" - 20	1"	1-3/4"	1"
U75	1/4" - 20	1-1/8"	2"	1"
U100	1/4" - 20	1-1/2"	2-3/4"	1-3/8"
U125	5/16" - 18	1-3/4"	3"	1-1/4"
U150	5/16" - 18	2"	2-11/16"	1-1/4"
U200	5/16" - 18	2-1/2"	3-3/16"	1-1/4"
U250	3/8" - 16	3"	3-5/8"	1-1/4"
U300	3/8" - 16	3-1/2"	4-1/2"	1-1/4"
U350	1/2" - 13	4"	5-1/2"	1-1/2"
U400	1/2" - 13	4-1/2"	7"	2-1/4"