


T-550A IMPROVED FLOW AND ORIGINAL T-550 REPAIR PARTS

In addition to Replacement Cartridges for the Current **T-550A Improved Flow** sillcock, Legend also offers Retro-fit Cartridges for **Original T-550** sillcocks manufactured before 2008. These cartridges are NOT interchangeable. **To enable you to identify which product you have installed and to order the correct replacement parts we've provided the following Information.**

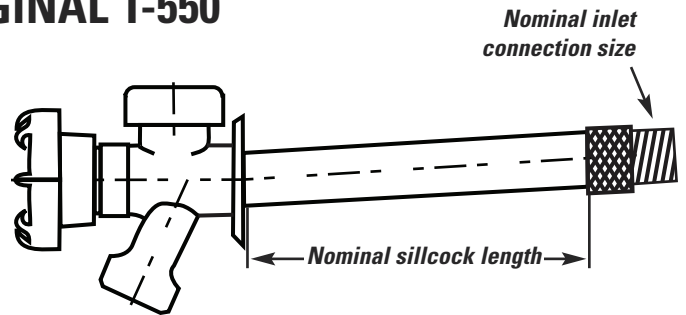

EXAMPLE: 1/2" x 10" T-550A; "1/2"" refers to the nominal inlet connection size and "10"" refers to the nominal length

T-550A REPAIR PARTS

T-550A Improved Flow Frost Free Sillcock



The T-550A IMPROVED FLOW I.D. disc is **Black** with Silver "LEGEND" lettering and includes the patent marking **Pat. 5.392.805 D527.797**.

The **inlet connection** is straight, with a round, **knurled wrench pad**, versus wrench flats.

If your product matches this description please choose a replacement cartridge from the chart at the right, or other replacement parts, as illustrated below

If your product does not match this description proceed to page 2. Please contact Legend Valve with any questions.

Replacement Cartridges for Improved Flow T-550A

Sillcock length	CARTRIDGE Length w/ handle	Length w/o handle	Cartridge replacement part #
4"	8-1/2"	7-3/4"	108-904A
6"	10-1/2"	9-3/4"	108-906A
8"	12-1/2"	11-3/4"	108-908A
10"	14-1/2"	13-3/4"	108-910A
12"	16-1/2"	15-3/4"	108-912A
14"	18-1/2"	17-3/4"	108-914A

Note: ONE o-ring and two tabs at the end of the cartridge



Pictured
T-550A Improved Flow
Exploded view

**108-904A, 108-906A,
108-908A, 108-910A,
108-912A, 108-914A**
Cartridge

108-902
Siding
Wedge

Cap

Body

Piston

108-903
Vacuum
Breaker Kit

108-904

108-162
Handle, Screw & Disc

Note: If your product does not match this description proceed to page 2. Please contact Legend Valve with any questions.

T-550 REPAIR PARTS

T-550 Original Frost Free Sillcock



The ORIGINAL T-550 I.D. disc is Silver with Black "LEGEND" lettering and includes only the phrase "Pat. Pend."

The inlet connection is tapered, with six wrench flats, versus a knurled wrench pad.

If your product matches this description please choose a replacement cartridge from the chart at the right, or other replacement parts, as illustrated below.

Note: If your product does not match this description return to page 1. Please contact Legend Valve with any questions.

Retro-Fit Cartridges for Original T-550

Sillcock length	RETRO-FIT CARTRIDGE Length w/ handle	RETRO-FIT CARTRIDGE Length w/o handle	Cartridge replacement part #
4"	8-1/2"	7-5/8"	108-904AR
6"	10-1/2"	9-5/8"	108-906AR
8"	12-1/2"	11-5/8"	108-908AR
10"	14-1/2"	13-5/8"	108-910AR
12"	16-1/2"	15-5/8"	108-912AR
14"	18-1/2"	17-5/8"	108-914AR



Note: TWO o-rings at the end of the cartridge.

Note: The original T-550 incorporates a detachable cartridge attached by the stainless-steel Phillips-head screw at the back of the stem (arrow), permitting cartridge removal from the stem. The replacement retro-fit cartridge eliminates this feature; the stem and cartridge are now one piece.

Pictured
Original T-550
Exploded view

108-902
Siding Wedge

Cap

Body

Piston

108-903
Vacuum Breaker Kit

**108-904AR, 108-906AR,
108-908AR, 108-910AR,
108-912AR, 108-914AR**
Retro-fit replacement cartridge

Note: On retro-fit cartridge stem and cartridge are now one piece.

108-904

108-162
Handle, Screw & Disc

Note: If your product does not match this description return to page 1. Please contact Legend Valve with any questions.