

# MAC FAUCETS

The Widest Selection of Decorative Automatic Faucets

## *Industry Standard™* Automatic Urinal Flush Valve



### **Models: AUV-2 Complete Valve**

**Model: AUV-2B Flush Valve Only (Retrofit Applications for Sloan, Zurn, Toto)**

#### **Package Includes**

*Automatic Flush Valve*

*3/4" Stop Valve*

*Supply Flange with  
Sweat Solder*

*3/4"-9" Vacuum  
Breaker Assembly*

*Urinal Spud Coupling*

*Batteries Pre-installed*

*All the hardware necessary for  
satisfactory installation*

ASSI 1037

ANSI/ASME  
A112.19.6

Installation  
Conforms to ADA  
Requirement


### **Featuring:** (AUV-2)

- **Solid Brass Body.**
- **Solid Brass, Trouble Free Piston Valve.**
- **Battery Powered (4 Standard AA Batteries).**
- **Solid Brass Stop.**
- **Piston Type Valving System.**
- Complete Mounting Hardware.
- Hermetically Sealed Sensor and electronics.
- Visible Low Battery Indicator Built into Sensor Capsule.
- **Available in 20 Finishes.**

## SPECIFICATIONS AND DIMENSIONS

MODEL:	<b>AUV-2</b>
BODY:	SOLID BRASS
STOP:	SOLID BRASS
SPUD:	3/4" - 9" LONG WITH VACUUM BREAKER
POWER:	4 AA ALKALINE BATTERIES
SOLENOID VALVE:	6 VOLT MAGNET LATCHING
WORKING WATER PRESSURE:	1 PSI - 100 PSI
WATER INLET SIZE:	3/4" AT STOP
WATER OUTLET SIZE:	1-1/2" AT SPUD
WATER FLOW CONTROL:	YES, AT STOP
FLUSH CYCLE:	1.0 GPF/3.785 LPF OPTION AVAILABLE
VALVING SYSTEM:	PISTON TYPE
STRAINER:	50 MESH
SENSOR TYPE AND LOCATION:	ACTIVE INFRARED, BODY MOUNT
SENSOR MICROPROCESSOR:	DIGITAL, PUG AND PLAY
SENSING ZONE:	8" TO 32"

### All Dimensions in Inches

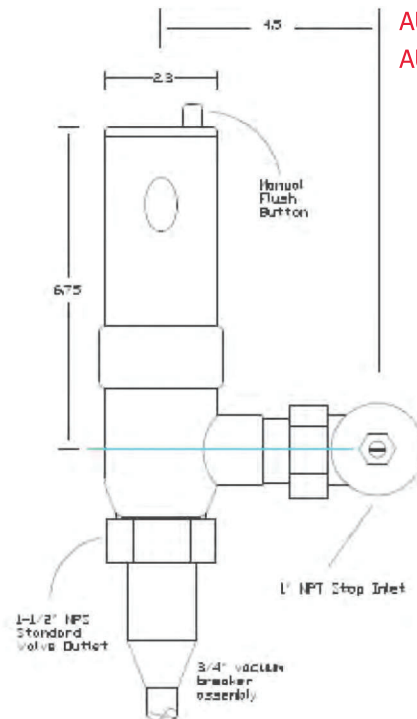

### Model:

- AUV-2 Urinal Flush Valve 1.0 GPF water use
- AUV-2-0.5 Urinal Flush Valve 0.5 GPF water use
- AUV-2-0.25 Urinal Flush Valve 0.25 GPF water use
- AUV-2-0.125 Urinal Flush Valve 0.125 GPF water use