



# Single Sided Towel Bar

## Installation Manual


### ► Measurements

CODE	Material	C/C
SDTRDS07524XXX	SUS304	24"

\*Available in several finishes

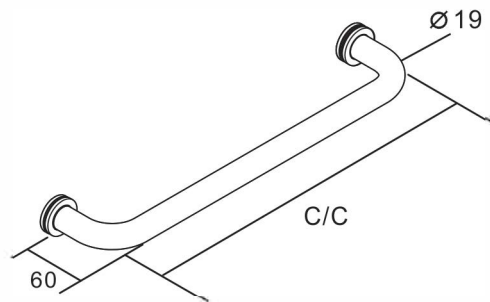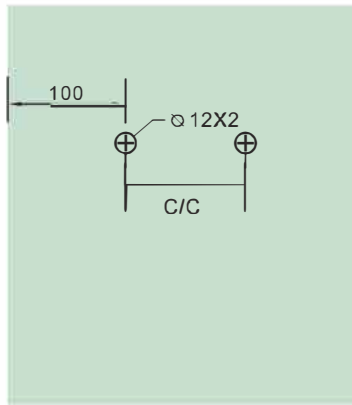

### ► Components

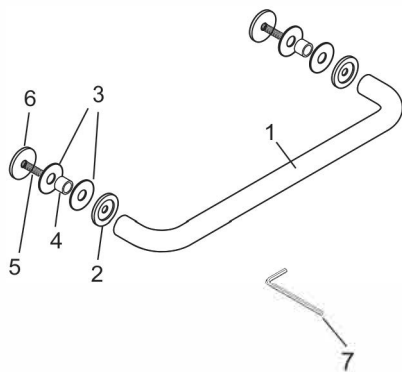


#	Name	Qty
1	Handle	1
2	Metal Washer dia32mm	2
3	Gasket	4
4	Plastic Washer	2
5	Screw M6x30mm	2
6	Knob dia32mm	2
7	Allen Key 3mm	1

# Single Sided Towel Bar


## Installation Manual

Install the towel bar on the needed side

\* Use the 50mm screw for glass doors 6-12mm thick

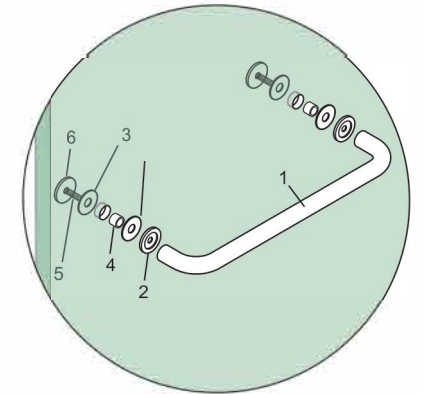

Tighten knob to finish the installation by allen key.

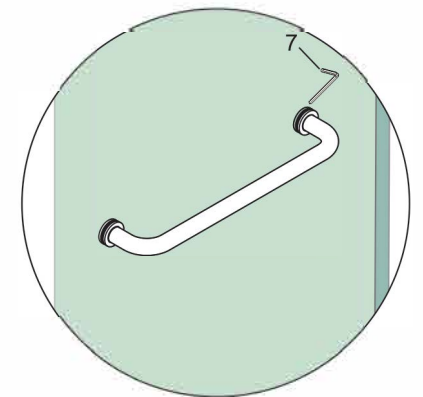



## Porte-serviettes

### Instructions d'installation


#### ► Dimensions

CODE	Matériel	C/C
SDTRDS07524XXX	SUS304	24"

\*Plusieurs finis disponible

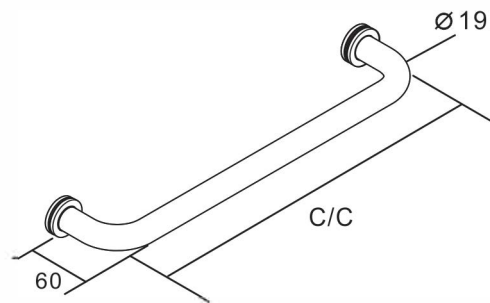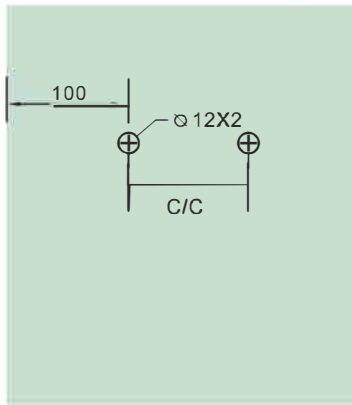

#### ► Composantes

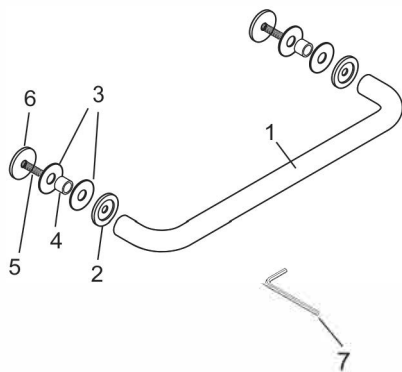


#	Nom	Qté
1	Poignée	1
2	Rondelle dia32mm	2
3	Joint	4
4	Bague plastique	2
5	Vis M6x30mm	2
6	Bouton dia32mm	2
7	clé Allen 3mm	1

## Porte-serviettes

### Instructions d'installation

Installez le porte-serviettes du côté nécessaire

\* Utilisez la vis de 50 mm pour les portes en verre de 6 à 12 mm d'épaisseur

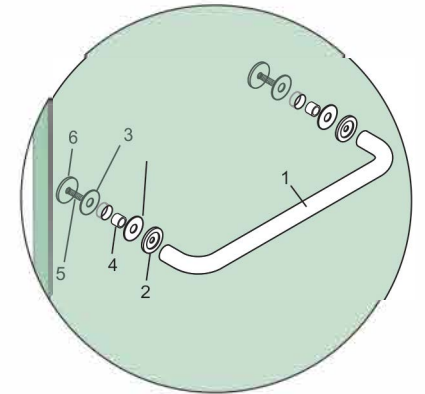

Serrez le bouton pour terminer l'installation par clé allen.

