



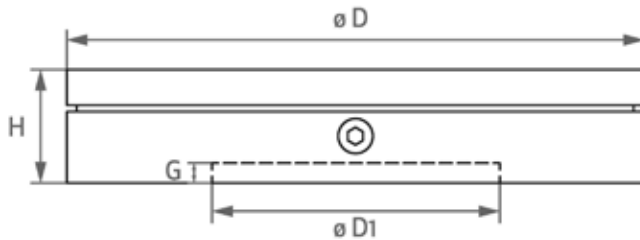

Magnetic Products, Inc.
Highland, Michigan | mpimagnet.com

Rare Earth Round Chuck

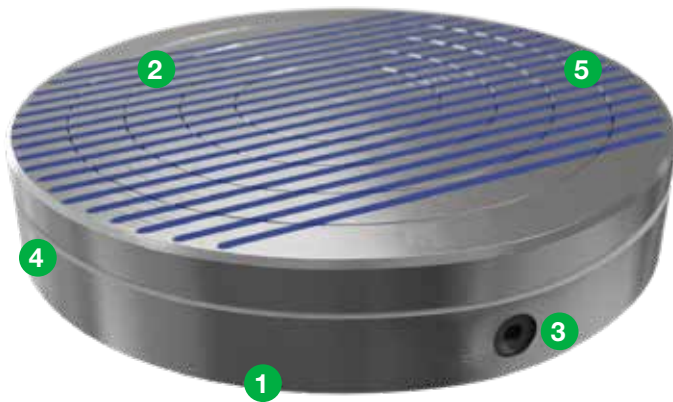

- 1 Solid steel body
- 2 Top plate with parallel pole configuration
- 3 Continuous adjustment of the holding force
- 4 Waterproof design
- 5 Double magnetic system

Longer life span top plate regrinding limit (.4in compared to .236in with Ferromax)

Low height

One (1) year warranty for the magnetic system

Manufactured in Europe to the highest quality standards

Application: Circular grinding

Technology: Permanent

Chuck dimensions: from 6in

Holding Force: 160N/cm² - 232lbs/in²

Minimum workpiece size: 1x1x0.3in

Regrinding limit: 0.4in

Pole pitch: T0.50.3+0.2in (steel/epoxy) or
T0.60.4+0.2in (steel/epoxy)

Poles: Parallel

Part Number	Description	Diameter (IN)	Height (IN)	G (IN)	D1 (IN)	Weight (LBS)
MAX-155-REN*	6" Rare Earth Round Chuck	6	2.2	0.2	2	19.8
MAX-200-REN*	8" Rare Earth Round Chuck	8	2.2	0.2	2.4	33.1
MAX-250-REN*	10" Rare Earth Round Chuck	10	2.2	0.2	3.2	48.5
MAX-300-REN*	12" Rare Earth Round Chuck	12	2.2	0.24	5.9	70.6
MAX-350REN	14" Rare Earth Round Chuck	14	2.2	0.24	6.7	94.8
MAX-400-REN	16" Rare Earth Round Chuck	16	2.2	0.24	7.9	123.5

Specifications subject to change • * Items stocked F.O.B. Highland, MI