
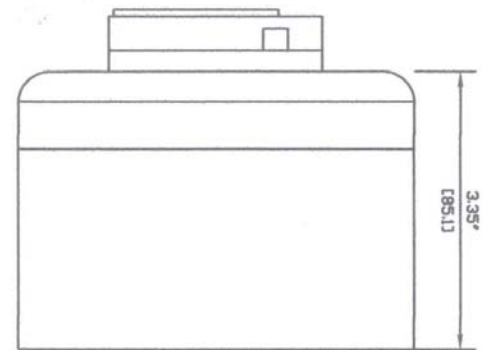
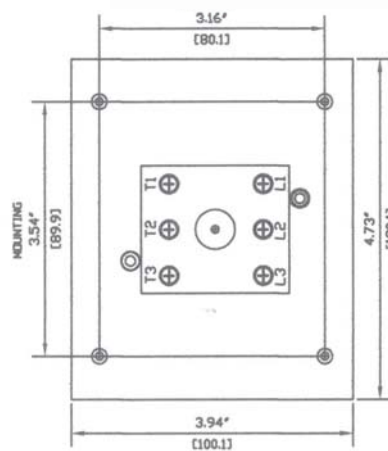
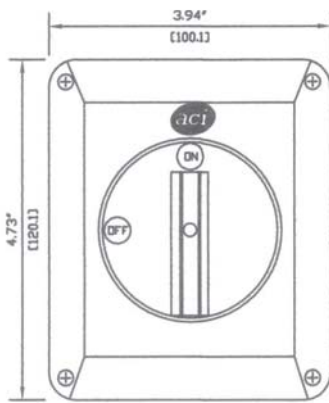


Switch Enclosed Non-Fused Disconnect Switch

UL 508 Listed, Motor Disconnect
& Manual Motor Controller

Phone 941.739.0879

2082 58th Ave. Circle E.
Bradenton, FL 34203

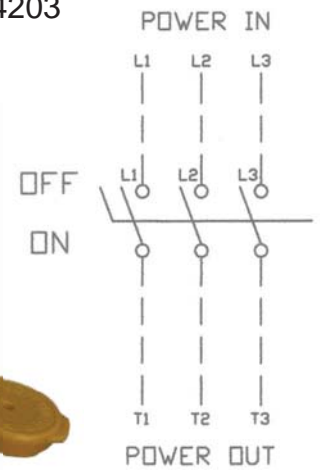

- Compact Space Saving Design
- Enclosed Switch - Ready to Mount
- Gasketed Non - Metallic 4X High Visibility Enclosure
- IP 65 Thermoplastic UL 50
- Yellow/Red Lockable Handle accepts up to 3 padlocks or tags per OSHA 1910.147, OFF-ON Legend
- 90 0 Switching, maintained
- Three Poles (Addition Pole & Auxiliary Contacts Available)
- UL 508 Listed as:
 - A. Manual Motor Controller
 - B. Manual Motor Controller for use as a Motor Disconnect

Warranty:

This Equipment is warranted to be free from defects in material and workmanship for a period of **two years** from the date of original shipment.

AMP Rating	Enclosure Size			Horsepower Ratings						
				120V	230V	200/208V	230V	460V	575V	
32	4.73" 120mm	3.94" 100mm	3.35" 85mm	1.5	3	7.5	7.5	10	15	

PROJECT			ARCHITECT		
CONTRACTOR	DATE	SUBMITTED BY		ENGINEER	
SPECIFICATION					
RELATED FAN POSITION	MODEL #	QTY	NOTES		