




PRODUCT DESCRIPTION

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

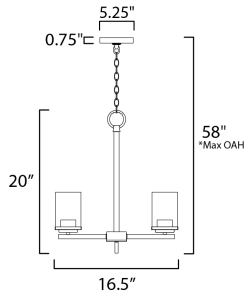

*max overall height




MEASUREMENTS

- DIMENSION : 16.5" L x 16.5" W x 20" H
- MAX OAH : 58" OAH
- CANOPY : 5.25" W x 0.75" H x 5.25" L
- HANGING WEIGHT : 6.24 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 3 x 60W Incandescent E26 Medium , 180W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE :

FINISHES OPTION

-  Black
-  Satin Brass
-  Satin Nickel

GLASS

Clear CL

MATERIAL

Steel + Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

ADJUSTABLE
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com