



PRODUCT DESCRIPTION

Minimalistic frames in a variety of brilliant finishes with your choice of either frosted or clear glass shades. While its sleek simplicity are modern in design, the Corona perfectly shines in any indoor application or style.

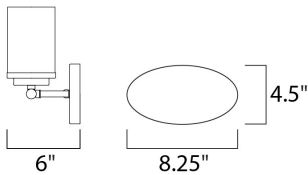


MEASUREMENTS






- DIMENSION : 19.25" W x 9" H x 6" Ext
- BACK PLATE : 6.75" HCO
- CANOPY : 4.5" W x 0.79" H x 8.25" L
- HANGING WEIGHT : 2.9 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 3 x 60W Incandescent E26 Medium , 180W Total
- BULB INCLUDED : (Not Included)
- LIGHTING_DIRECTION : Omni



FINISHES OPTION

-  Black
-  Oil Rubbed Bronze
-  Polished Chrome
-  Satin Brass
-  Satin Nickel

GLASS

Clear CL

MATERIAL

Steel + Glass

RATINGS

cETLus
Damp Location



ADDITIONAL

INSTALL UP/DOWN: Up/Down
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

PHOTOMETRIC: Report Found Online

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269
P. 626.956.4200 | F. 626.956.4225 | maximlighting.com