



#### PRODUCT DESCRIPTION

Understated elegance and convenience in its design, the simple curved arms of the Bristol collection outstretch in elongated proportions that terminate at a tapered Satin White glass shade. Designed to emulate a traditional fabric shade, the material being glass adds the element of easy maintenance and allows for upward and downward facing light installations. The single tiered wider diameters on the chandeliers also offer an upscale country living addition to the collection. Available in various finishes of Satin Nickel, Satin Brass, or black tones including a textured Anthracite finish on the chandeliers and sconces.


#### MEASUREMENTS

DIMENSION : 20.75" W x 10" H x 6" Ext  
 BACK PLATE : 4.75" W x 4.75" H x 7.75" HCO  
 HANGING WEIGHT : 3.55 lb

#### LAMPING

INPUT VOLTAGE : 120V  
 BULB : 3 x 60W Incandescent E26 Medium , 180W Total  
 BULB INCLUDED : (Not Included)

#### FINISHES OPTION

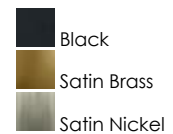

#### GLASS

Satin White SW

#### MATERIAL

Steel, Glass

#### RATINGS

Damp Location



#### ADDITIONAL

INSTALL UP/DOWN: Up/Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com