 
 




PRODUCT DESCRIPTION

Sweeping metal accents links create classic curves on a minimalist chandelier. Available in hand-rubbed Chestnut Bronze or elegant Gold Leaf finishes. Add crystal accents to elevate the design for a more extravagant glamour. The design manages to evoke French Country charm and enchants any room it illuminates.

FINISHES OPTION

-  Chestnut Bronze
-  Gold Leaf

GLASS

Crystal CRY

MATERIAL

Iron & Crystal

RATINGS

cULus
Dry Location



ADDITIONAL


INSTALL UP/DOWN: Up
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

MEASUREMENTS

- DIMENSION : 36" L x 36" W x 30" H
- MAX OAH : 105.5" OAH
- CANOPY : 1.14" H x 5.1" L
- HANGING WEIGHT : 5.3 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 8 x 60W Incandescent E12 Candelabra , 480W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y
- LIGHTING_DIRECTION : Up

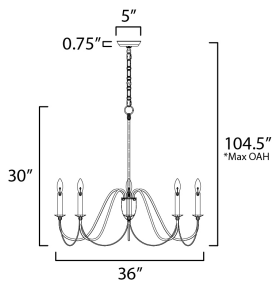

*max overall height

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com