




#### PRODUCT DESCRIPTION

Direct the light exactly where you want it using the articulated arms and metal shades of the Library series. At the backplate, the arm pivots left/right and up/down to direct the light. Additional articulated arms angle the shade or extend/contract the distance of the light source from the wall. Available in Polished Nickel, Black and Heritage Brass finishes, the Library collection evokes industrial era classicism perfect for use as a task light or accent light. Complimentary table and floor lamps complete the collection.

#### FINISHES OPTION

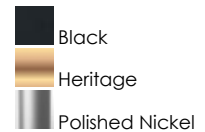

#### MATERIAL

Brass, Steel


#### RATINGS

cETLus  
Dry Location



#### ADDITIONAL

OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

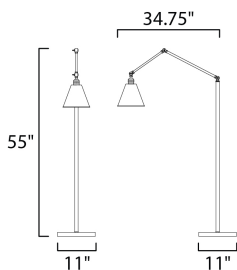

#### MEASUREMENTS

DIMENSION : 34.75" L x 11" W x 55" H  
HANGING WEIGHT : 17.82 lb

#### LAMPING

INPUT VOLTAGE : 120V  
BULB : 1 x 100W Incandescent E26 Medium , 100W Total  
BULB INCLUDED : (Not Included)  
DIMMABLE : No  
LIGHTING\_DIRECTION : Directional

Always consult a qualified electrician before installing any lighting product.