



PRODUCT DESCRIPTION


Tasteful globes constructed of metal and glass halves are combined and suspended by an arc-shaped yoke structure. The top dome of robust steel support lower halves of Satin White glass shades that twist lock on for convenience of installation and maintenance. Available in Matte Black with contrasting Weathered Brass or Satin Nickel with Satin Brass two tone finishes, the series includes a full range of products including flush mount, semi-flush mount, single and multi-pendant configurations, and spec-worthy sconces. This attractive design is sure to enhance your projects most needed spaces with an enduring appeal to the design that works in a variety of aesthetics.

MEASUREMENTS

DIMENSION : 9.5" W x 7.5" H x 4.25" Ext
 MAX OAH : 7" W x 0.5" H
 HANGING WEIGHT : 2.03 lb


LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y
 LIGHTING_DIRECTION : Down

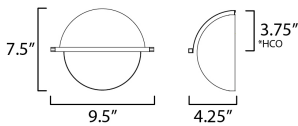

*Height from center of outlet to the top of the fixture

FINISHES OPTION

-  Black/Weathered Brass
-  Satin Nickel / Satin Brass

GLASS

Satin White SW

MATERIAL

Steel, Glass

RATINGS

cETLus
 Dry Location



ADDITIONAL

INSTALL UP/DOWN: Down
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com