



PRODUCT DESCRIPTION


Dramatic and opulent, light sources shine through exquisite Clear scalloped glass hurricane shades as they seemingly float on unique metal prongs finished in Antique Brass. The brass accents are contrasted with a Black frame configured in cascading pendant forms, classically tiered chandeliers and elongated individual pendants. The expansive variety of configurations present a configuration for all the interior spaces of a home, be it over dining tables or used in the entry, kitchen, or over the vanity. The collection also includes ADA wall sconces that are left and right oriented for symmetrical installations bedside or beside a mirror.

MEASUREMENTS

- DIMENSION : 45.25" L x 12" W x 14" H
- MAX OAH : 51" OAH
- CANOPY : 5.5" W x 1.5" H x 27.5" L
- HANGING WEIGHT : 17 lb

LAMPING

- INPUT VOLTAGE : 120V
- LUMENS : 1,800 Rated (1,250 Del.)
- BULB : 1 x 1.8W LED G4 , 18W Total
- BULB INCLUDED : (Included)
- DIMMABLE : Y
- CRI : 90 CRI
- COLOR_TEMP : 3000K

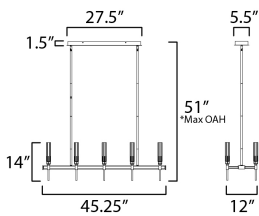

*max overall height

FINISHES OPTION



GLASS

Clear CL

MATERIAL

Steel, Glass

RATINGS

cETLus
Dry Location



ADDITIONAL

RATED LIFE 25000 Hours
OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com