







**PRODUCT DESCRIPTION**

Low sloping arms of rectilinear tubing is finished in a variety of options that include Satin Nickel, Oil Rubbed Bronze, Matte Black, and a contemporary Satin Brass finish. Tall, cylindrical Satin White glass shades soften the light source within. Offered in a variety of configurations that include chandeliers, sconces, and a semi-flush pendant that may be used as a foyer pendant, has become a proven popular choice among builders.

**FINISHES OPTION**

-  Black
-  Oil Rubbed Bronze
-  Satin Brass
-  Satin Nickel

**GLASS**

Satin White SW

**MATERIAL**

Steel, Glass


**RATINGS**

cETLus  
Dry Location



**ADDITIONAL**

SLOPE: 70  
OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

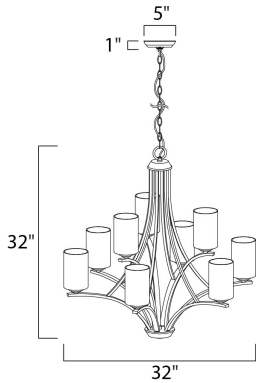

**MEASUREMENTS**

- DIMENSION : 32" L x 32" W x 32" H
- MAX OAH : 108" OAH
- CANOPY : 5" W x 0.78" H x 5" L
- HANGING WEIGHT : 15.75 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- BULB : 9 x 60W Incandescent E26 Medium , 540W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com