



PRODUCT DESCRIPTION


The timeless Empire chandelier shape styled in timeworn, natural finishes uses durable steel in a Driftwood finish that includes a spherical ornament in matching finish. The arms curve steeply, swept lower than the chandelier's center, emphasizing the chandelier's height while mitered angles at its top accentuate the thickness of the barrel-like planks. Exposed candelabra lamps on Anthracite candle covers adding texture and contrast. The result of the organic wood tones reduces the formality of the classical shape making the elegance of this design more inviting.

MEASUREMENTS

DIMENSION : 12" W x 12.5" H x 6.75" Ext
 MAX OAH : 6" W x 0.75" H
 HANGING WEIGHT : 2.2 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 2 x 60W Incandescent E12 Candelabra , 120W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y
 LIGHTING_DIRECTION : Up

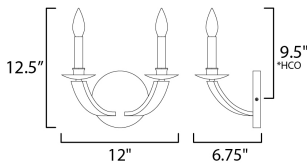

*height from center of outlet to the top of the fixture

FINISHES OPTION

 Driftwood/Anthracite

MATERIAL

Steel

RATINGS

cETLus
 Dry Location



ADDITIONAL

INSTALL UP/DOWN: Up
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com