



**PRODUCT DESCRIPTION**


Retro configurations of Mid-Century Modern perforated metal designs inspire this collection of pendants, wall and ceiling mounts complete in a two tone powder coat finish. The spun metal shades are punched with large circular perforations that scatter a pattern of light when lit. Finished in a clean, two-tone Matte White and Black powder coat, these pieces add cheerful character to their space. The oversized shades on the wall sconce and portable lamps also feature a swivel joint that allow you to position the shade and direct the light with ease. A convenient switch on the back of the shade operates a 3-step dimmer to adjust the lamp's brightness at the touch of a button.

**MEASUREMENTS**

DIMENSION : 7.25" L x 6.25" W x 11.5" H  
 MAX OAH : 5" W x 5" H  
 HANGING WEIGHT : 2.2 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 1 x 40W Incandescent E26 Medium , 40W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : 3 Step Touch  
 LIGHTING\_DIRECTION : Directional

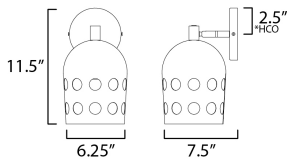

\*height to center of outlet to the top of the fixture

**FINISHES OPTION**

 Black

**GLASS**

White WT

**MATERIAL**

Steel

**RATINGS**

cETLus  
 Damp Location



**ADDITIONAL**

INSTALL UP/DOWN: Down  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com