



PRODUCT DESCRIPTION


Retro configurations of Mid-Century Modern perforated metal designs inspire this collection of pendants, wall and ceiling mounts complete in a two tone powder coat finish. The spun metal shades are punched with large circular perforations that scatter a pattern of light when lit. Finished in a clean, two-tone Matte White and Black powder coat, these pieces add cheerful character to their space. The oversized shades on the wall sconce and portable lamps also feature a swivel joint that allow you to position the shade and direct the light with ease. A convenient switch on the back of the shade operates a 3-step dimmer to adjust the lamp's brightness at the touch of a button.

MEASUREMENTS

DIMENSION : 8.5" W x 12.5" H x 10.25" Ext
 HANGING WEIGHT : 3.3 lb

LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 40W Incandescent E26 Medium , 40W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : 3 Step Touch
 LIGHTING_DIRECTION : Directional

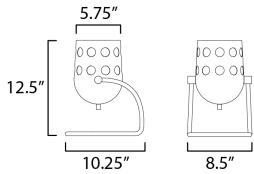

FINISHES OPTION

 Black

GLASS

White WT

MATERIAL

Steel

RATINGS

cETLus
 Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com