



**PRODUCT DESCRIPTION**


Metal shades finished in a warm Heritage Brass are accented with Dark Bronze metal straps and Tobacco Brown leather wrapped details. Recessed within the metal shades, a frosted glass diffuser softly casts the LED light source within. Paddles on every shade allow the light to easily be directed upward or downwards. With the accompanying wall sconce in the collection, a touch switch is located on its top and the convenient paddle at its end allows you to direct the light source where needed. Tasteful and timeless, the reimagined classic metal drum shades are elevated with technology and convenient features. Perfect for entries, eating areas, and bedside applications.

**MEASUREMENTS**

- DIMENSION : 28" L x 28" W x 12" H
- MAX OAH : 56.25" OAH
- CANOPY : 5.5" W x 0.75" H x 5.5" L
- HANGING WEIGHT : 7.26 lb

**LAMPING**

- INPUT VOLTAGE : 120V
- LUMENS : 2,700 Rated (2,400 Del.)
- BULB : 5 x 6W LED AC Integrated , 30W Total
- BULB INCLUDED : (Integrated)
- DIMMABLE :
- CRI : 90 CRI
- COLOR\_TEMP : 3000K
- LIGHTING\_DIRECTION : Directional

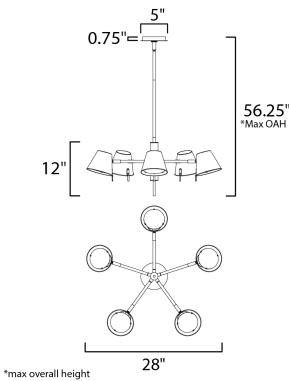

**FINISHES OPTION**

Dark Bronze, Leather, Heritage Brass

**MATERIAL**

Steel, Acrylic

**RATINGS**

Dry Location



**ADDITIONAL**

OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com