



PRODUCT DESCRIPTION

Metal shades finished in a warm Heritage Brass are accented with Dark Bronze metal straps and Tobacco Brown leather wrapped details. Recessed within the metal shades, a frosted glass diffuser softly casts the LED light source within. Paddles on every shade allow the light to easily be directed upward or downwards. With the accompanying wall sconce in the collection, a touch switch is located on its top and the convenient paddle at its end allows you to direct the light source where needed. Tasteful and timeless, the reimagined classic metal drum shades are elevated with technology and convenient features. Perfect for entries, eating areas, and bedside applications.

 
MEASUREMENTS

DIMENSION : 34" L x 34" W x 16.75" H
 MAX OAH : 61" OAH
 CANOPY : 5.5" W 5.5" L
 HANGING WEIGHT : 11.242 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 4,800 Rated (4,000 Del.)
 BULB : 9 x 6W LED AC Integrated , 54W Total
 BULB INCLUDED : (Integrated)
 DIMMABLE :
 CRI : 90 CRI
 COLOR_TEMP : 3000K
 LIGHTING_DIRECTION : Directional

FINISHES OPTION

 Dark Bronze, Leather, Heritage Brass

MATERIAL

Steel, Acrylic


RATINGS

Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

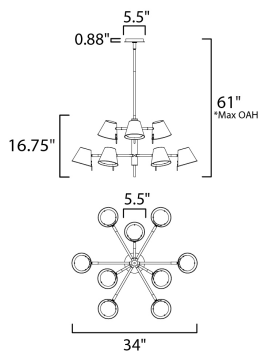

*max overall height

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com