



PRODUCT DESCRIPTION


Dramatically modern, individually supported rods run through a series of flat circular disks adding interest to the elongated adjustable arms that can be configured according to how you choose to position them. Finished in Naturally Aged Brass and Matte Black finishes, the frames terminate at their ends with LED tubular lamps supplied and shrouded in long cylindrical glass shades secured with pins at the fixture's sockets. The characteristic details and warm filament light source add industrial flair making the collection's modern configuration suitable to a wider array of transitional styling.

MEASUREMENTS

DIMENSION : 36" L x 36" W x 15.75" H
 MAX OAH : 59" OAH
 CANOPY : 5" W x 0.75" H x 5" L
 HANGING WEIGHT : 8.8 lb

LAMPING

INPUT VOLTAGE : 120V
 LUMENS : 2,400 Rated (1,920 Del.)
 BULB : 4 x 6W LED E26 Medium , 24W Total
 BULB INCLUDED : (Included)
 DIMMABLE : Y
 CRI : 90 CRI
 COLOR_TEMP : 2700K

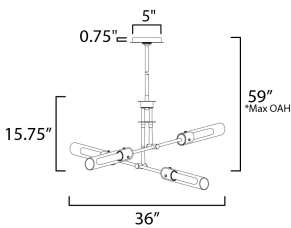

*max overall height

FINISHES OPTION

- Black
- Natural Aged Brass

GLASS

Clear CL

MATERIAL

Steel, Glass

RATINGS

cETLus
 Dry Location



ADDITIONAL

RATED LIFE 25000 Hours
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com