



PRODUCT DESCRIPTION

Effortlessly elegant, the biophilic details that adorn this classic chandelier transports you to an oasis indoors. The design, whether brilliantly gilt in Gold Leaf or hand painted in a dramatically textural Anthracite finish, exudes a timeless quality that is sure to please. The graceful form of these fixtures is constructed of slender metal tubes that sprout from a spherical collector at the center and Off-White metal candle covers that are designed to last.

FINISHES OPTION

-  Anthracite
-  Gold Leaf

MATERIAL

Steel


RATINGS

cETLus
Dry Location



ADDITIONAL

OPERATING TEMPERATURE:
-20°C (-4°F), 40°C (104°F)

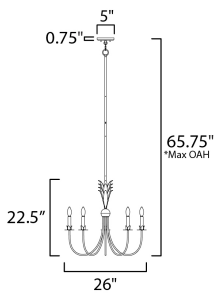

MEASUREMENTS

- DIMENSION : 26" L x 26" W x 22.5" H
- MAX OAH : 65.75" OAH
- CANOPY : 5" W x 0.75" H x 5" L
- HANGING WEIGHT : 5.94 lb

LAMPING

- INPUT VOLTAGE : 120V
- BULB : 5 x 60W Incandescent E12 Candelabra , 300W Total
- BULB INCLUDED : (Not Included)
- DIMMABLE : Y

*max overall height

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com