




**PRODUCT DESCRIPTION**

Squared columns in Matte Black finish tower above the cylindrical glass shade rated for outdoor applications. A rectangular hook detail carries the square form through to the backplate. A modern interpretation of a bell tower, these outdoor pendants and sconces are a cleaned up, transitional look for exteriors.

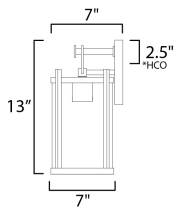

**MEASUREMENTS**

DIMENSION : 7" W x 13" H x 7" Ext  
 BACK PLATE : 4.75" W x 6.25" H x 2.5" HCO  
 HANGING WEIGHT : 3.96 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Y  
 LIGHTING\_DIRECTION : Down

\*height from center of outlet to the top of the fixture

**FINISHES OPTION**

 Black

**GLASS**

Clear CL

**MATERIAL**

Aluminum, Glass

**RATINGS**

cETLus  
 Wet Location



**ADDITIONAL**

INSTALL UP/DOWN: Down  
 RATED LIFE 2500 Hours  
 OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com