




**PRODUCT DESCRIPTION**

A dual framed structure creates dimension on these outdoor lighting fixtures that is both contemporary and transitional. The construction consists of two frames of square tubing and squared components. The inner frame's Clear Seedy glass reduces glare from the light and appears dirt-free for longer periods. This is a comprehensive collection to brighten all areas of your outdoor space, available in various sized sconces as well as hanging and post configurations.

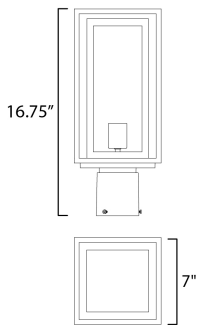

**MEASUREMENTS**

DIMENSION : 7" W x 16.75" H x 7" Ext  
 HANGING WEIGHT : 4.1 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Y

**FINISHES OPTION**

 Black

**GLASS**

Seedy CD

**MATERIAL**

Aluminum, Glass

**RATINGS**

cETLus  
 Wet Location



**ADDITIONAL**

OPERATING TEMPERATURE:  
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER  
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com