



**PRODUCT DESCRIPTION**

Hand-formed glass petals of Clear and Champagne-tint suspend from a tiered frame of gold and accented with petals of solid metal finished in Gold Leaf. Numerous candelabra sockets are strategically placed within the fixture to create glimmer and elegance to this majestic collection.

**FINISHES OPTION**



**GLASS**

Clear and Champagne CLCMP

**MATERIAL**

Steel, Glass

**RATINGS**

cETLus  
Dry Location



**ADDITIONAL**


OPERATING TEMPERATURE:  
-20°C (-4°F), 40°C (104°F)

**MEASUREMENTS**

DIMENSION : 32.5" L x 32.5" W x 37" H  
 MAX OAH : 80" OAH  
 CANOPY : 7" W x 1.5" H x 7" L  
 HANGING WEIGHT : 119.9 lb

**LAMPING**

INPUT VOLTAGE : 120V  
 BULB : 21 x 40W Incandescent E12 Candelabra , 840W Total  
 BULB INCLUDED : (Not Included)  
 DIMMABLE : Yes

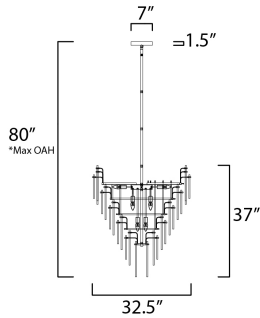

\*max overall height

Always consult a qualified electrician before installing any lighting product.



**WESTERN DISTRIBUTION CENTER (HEADQUARTER)**  
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

**EASTERN DISTRIBUTION CENTER**  
 4200 SHIRLEY DR. | ATLANTA, GA 30336

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com