



PRODUCT DESCRIPTION

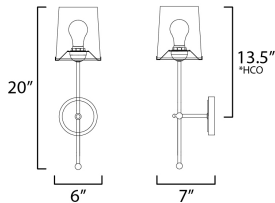
Satin White shades taper in a classic fabric shade shape and rest on elegantly thin frames of Satin Brass or Satin Nickel. They are supported secured by a mostly concealed structure with coordinating semicircular tabs that complement the spherical joints of the frame. The modern design details and updated shade materials refresh the outlook of a timeless chandelier though its use of thoughtful features.

MEASUREMENTS

DIMENSION : 6" W x 20" H x 7" Ext
 MAX OAH : 4.75" W x 4.75" H
 HANGING WEIGHT : 1.9 lb



LAMPING

INPUT VOLTAGE : 120V
 BULB : 1 x 60W Incandescent E26 Medium , 60W Total
 BULB INCLUDED : (Not Included)
 DIMMABLE : Y



*height to center of outlet to the top of the fixture

FINISHES OPTION

-  Satin Brass
-  Satin Nickel

GLASS

White WT

MATERIAL

Steel, Glass

RATINGS

cETLus
 Damp Location



ADDITIONAL

INSTALL UP/DOWN: Up
 OPERATING TEMPERATURE:
 -20°C (-4°F), 40°C (104°F)

Always consult a qualified electrician before installing any lighting product.



WESTERN DISTRIBUTION CENTER (HEADQUARTER)
 253 NORTH VINELAND AVE | CITY OF INDUSTRY, CA 91746

EASTERN DISTRIBUTION CENTER
 101 GARDNER PARK | PEACHTREE CITY, GA 30269

P. 626.956.4200 | F. 626.956.4225 | maximlighting.com